



SMD-Leuchtdioden

5050, klar


- Abstrahlwinkel 120 °
- Anschluss SMT
- Bauform 5050
- Linse wasserklar
- Temperatur 50°C für 3 sek / 30 °C für 3 min

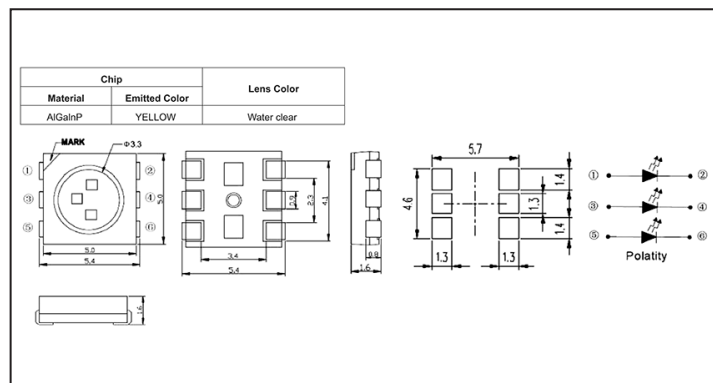


1577532

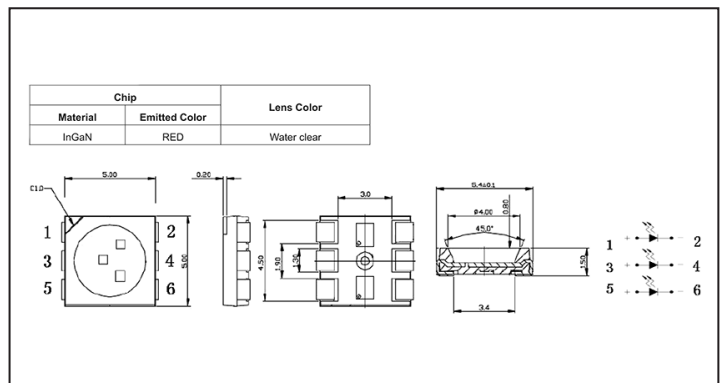


1577534

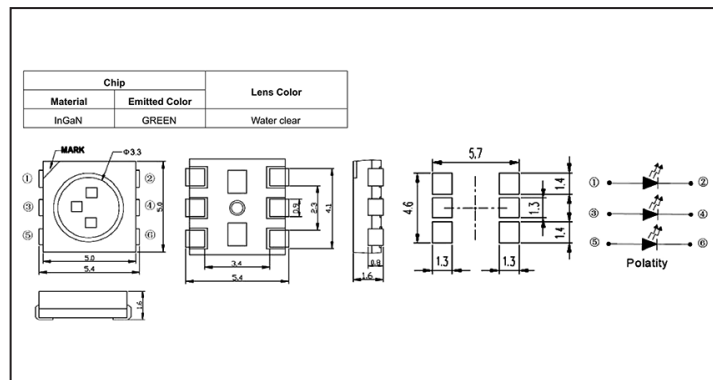


1577424

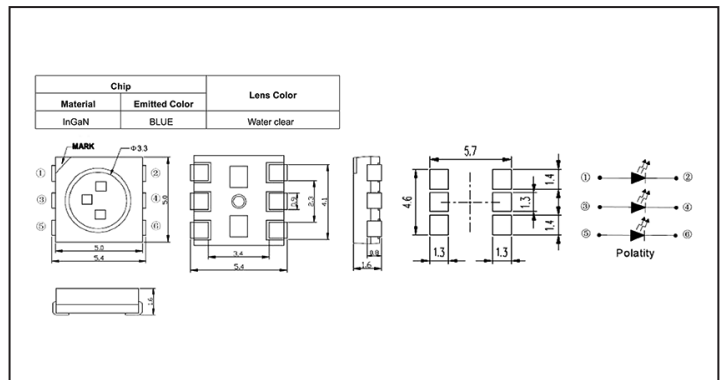

1577329

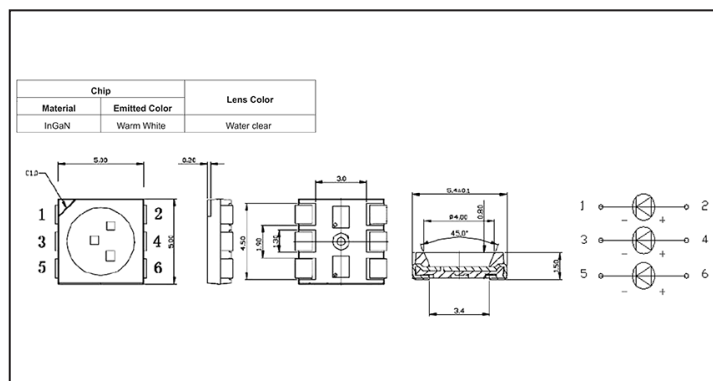


1577425

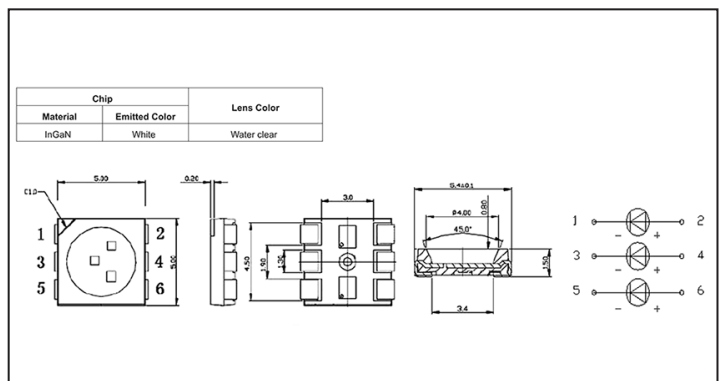

1577533

Datasheet

Item no. 1577423

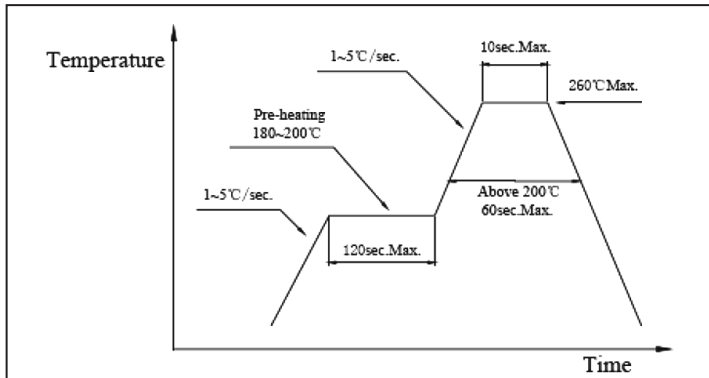

Artkbez:	Farbe:	Wellenlänge*:	Helligkeit*:	Farbtemperatur*:	Betriebsspannung*:
1577423	● rot	620 - 630 nm	2500 - 3500 mcd		1,9 V - 2,4 V
1577532	● gelb	585 - 595 nm	2500 - 3500 mcd		1,9 V - 2,4 V
1577329	● blau	460 - 470 nm	2500 - 3000 mcd		3 V - 3,4 V
1577424	● grün	520 - 525 nm	3000 - 4000 mcd		3 V - 3,4 V
1577533	○ weiß			6000 - 4500 K	3 V - 3,4 V
1577425	○ warmweiß			3000 - 4500 K	3 V - 3,4 V

*Betriebsstrom 20 mA