

ZYXEL

Zyxel GS-105BV5-EU0101F Netzwerk-Switch Unmanaged L2 Gigabit Ethernet (10/100/1000)

Marke : Zyxel

Artikel-Code: GS-105BV5-EU0101F

Produktname : GS-105BV5-EU0101F

- Unmanaged 5-Port Switch
 - Vollständige Abdeckung des Netzwerks
 - Wand- oder Desktop-Montage
 - QoS-Ports für reibungslosen VoIP- und Datenaustausch
 - Energiesparend nach IEEE 802.3az-Standard
- GS-100 Serie 5-Port/8-Port Unmanaged Switch



Zyxel GS-105BV5-EU0101F Netzwerk-Switch Unmanaged L2 Gigabit Ethernet (10/100/1000):


Plug-and-Play für Ihre tägliche Netzwerkverbindung

Ohne manuelle Konfiguration kann die GS-100-Serie die Datenübertragungsgeschwindigkeit für angeschlossene Netzwerkgeräte wie IP-Telefone, Netzwerkspeicher, PCs und Laptops im Netzwerk mit Gigabit-Geschwindigkeit erhöhen - einfach per Plug-and-Play.

Zyxel GS-105BV5-EU0101F. Switch-Typ: Unmanaged, Switch-Ebene: L2. Basic Switching RJ-45 Ethernet Ports-Typ: Gigabit Ethernet (10/100/1000), Anzahl der basisschaltenden RJ-45 Ethernet Ports: 5. MAC-Adressentabelle: 2000 Eintragungen, Routing-/Switching-Kapazität: 10 Gbit/s. Netzstandard: IEEE 802.3, IEEE 802.3u, IEEE 802.3x



Management-Funktionen		Datenübertragung	
Switch-Typ *	Unmanaged	Routing-/Switching-Kapazität *	10 Gbit/s
Switch-Ebene	L2	Transferrate	7,4 Mpps
Quality of Service (QoS) Support	✓	MAC-Adressentabelle *	2000 Eintragungen
Web-basiertes Management	✗	Design	
Cloud-verwaltet	✗	Rack-Einbau *	✗
Traffic-Klassifizierung	✓	Stapelbar *	✗
Anschlüsse und Schnittstellen		Energie	
Anzahl der basisschaltenden RJ-45 Ethernet Ports *	5	Energiequelle *	AC
Basic Switching RJ-45 Ethernet Ports-Typ *	Gigabit Ethernet (10/100/1000)	Netzteil enthalten *	✓
Netzwerk		Power over Ethernet (PoE)	
Netzstandard *	IEEE 802.3, IEEE 802.3u, IEEE 802.3x	Power over Ethernet (PoE) *	✗
10G-Unterstützung *	✗	Gewicht und Abmessungen	
		Breite	132 mm
		Tiefe	90 mm
		Höhe	27 mm
		Gewicht	280 g

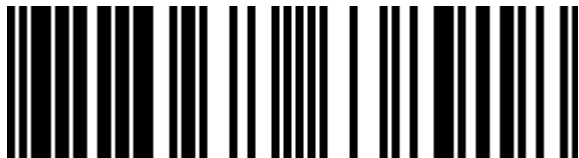

4718937638918

Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.

Publication date: 19-MAY-2025. Prints or copies of Information are only valid on the printed Publication date