


## Datenblatt / Data Sheet

### Hitzebeständiges Doppelklebeband

Heat Resistant Double Tape

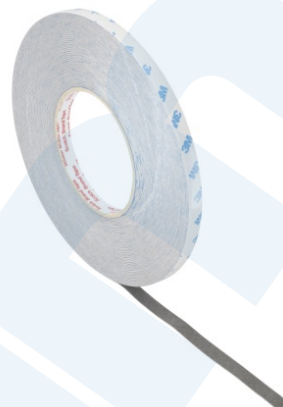

### Technische Daten / technical data

Bezeichnung / Description	Eigenschaften / Characteristics
Artikelnummer / Item no.	<b>30033009</b>
Klebebanddicke / Tape thickness	0.40mm
Farbe / Color	Grau / grey
Dicke der Schutzabdeckung / Liner thickness	0.14mm
Dichte / Density (g/cm <sup>3</sup> )	0.65 g
Druck / Compression (kg/cm <sup>2</sup> )	1.0 kg
Temperaturbereich / Temperature range	-30°C ~ 200°C
Klebkraft Festigkeit / Adhesion strength (kg/cm)	90° = 1.4 kg/cm (300mm/min) T = 1.1 kg/cm (300mm/min) Dehnbar / Tensile = 4.1 kg/cm <sup>2</sup> (10kg/30Sec.) Scherfestigkeit / Shear strength = 12.9 kg/cm <sup>2</sup>
Abmaße LxB / Dimensions LxW	33m x 9mm