



SPOT LED DIM*

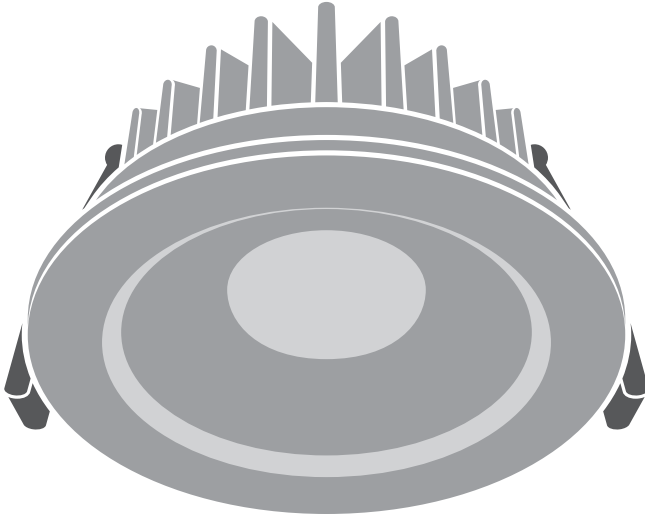

	EAN	Ø x h [mm]	W	lm	lm/W	K	I ₀ [mA]
SpotFP LED fix 8W/3000K WT DIM IP65	4058075127432	81 x 51	8	620	75	3000	170mA@27-42V 50V Max.
SpotFP LED fix 8W/4000K WT DIM IP65	4058075127555	81 x 51	8	670	80	4000	170mA@27-42V 50V Max.
SpotFP LED fix 8W/3000K SI DIM IP65	4058075127371	81 x 51	8	620	75	3000	170mA@27-42V 50V Max.
SpotFP LED fix 8W/4000K SI DIM IP65	4058075127494	81 x 51	8	670	80	4000	170mA@27-42V 50V Max.
Spot LED fix 8W/3000K WT DIM IP44	4058075127043	81 x 51	8	620	75	3000	170mA@27-42V 50V Max.
Spot LED fix 8W/4000K WT DIM IP44	4058075127104	81 x 51	8	670	80	4000	170mA@27-42V 50V Max.
Spot LED fix 8W/3000K SI DIM IP44	4058075126923	81 x 51	8	620	75	3000	170mA@27-42V 50V Max.
Spot LED fix 8W/4000K SI DIM IP44	4058075127067	81 x 51	8	670	80	4000	170mA@27-42V 50V Max.


	EAN	Δ (°C)	V _{AC}	Hz	IP	IK	PF	∠	R _a	⊞
SpotFP LED fix 8W/3000K WT DIM IP65	4058075127432	-20...+45	220-240V	50/60 Hz	65/20	06	≥ 0.9	36°	>80	0.3 kg
SpotFP LED fix 8W/4000K WT DIM IP65	4058075127555	-20...+45	220-240V	50/60 Hz	65/20	06	≥ 0.9	36°	>80	0.3 kg
SpotFP LED fix 8W/3000K SI DIM IP65	4058075127371	-20...+45	220-240V	50/60 Hz	65/20	06	≥ 0.9	36°	>80	0.3 kg
SpotFP LED fix 8W/4000K SI DIM IP65	4058075127494	-20...+45	220-240V	50/60 Hz	65/20	06	≥ 0.9	36°	>80	0.3 kg
Spot LED fix 8W/3000K WT DIM IP44	4058075127043	-20...+45	220-240V	50/60 Hz	44/20	06	≥ 0.9	36°	>80	0.3 kg
Spot LED fix 8W/4000K WT DIM IP44	4058075127104	-20...+45	220-240V	50/60 Hz	44/20	06	≥ 0.9	36°	>80	0.3 kg
Spot LED fix 8W/3000K SI DIM IP44	4058075126923	-20...+45	220-240V	50/60 Hz	44/20	06	≥ 0.9	36°	>80	0.3 kg
Spot LED fix 8W/4000K SI DIM IP44	4058075127067	-20...+45	220-240V	50/60 Hz	44/20	06	≥ 0.9	36°	>80	0.3 kg

1a

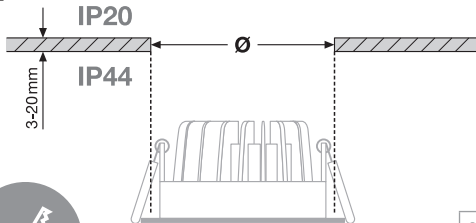


	Ø
Spot LED fix 8W/3000K WT DIM IP44	68 mm
Spot LED fix 8W/4000K WT DIM IP44	68 mm

1b

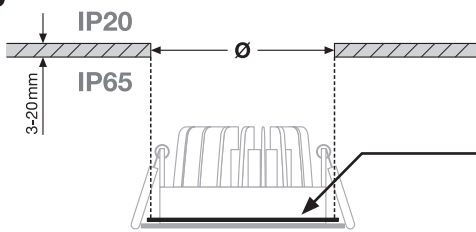


BS476-20:1978
BS476-21:1978

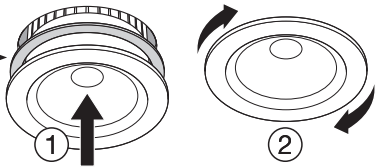








	Ø
SpotFP LED fix 8W/3000K WT DIM IP65	68 mm
SpotFP LED fix 8W/4000K WT DIM IP65	68 mm






2

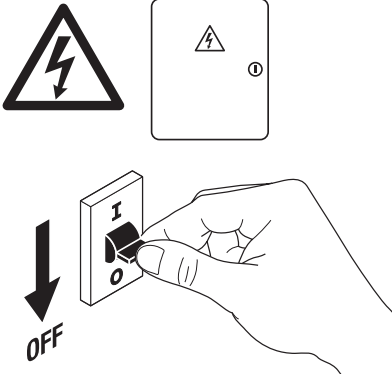

3

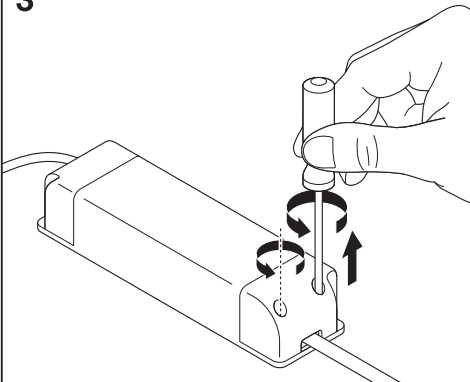

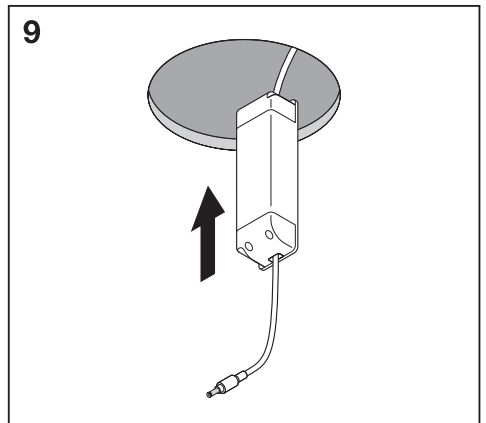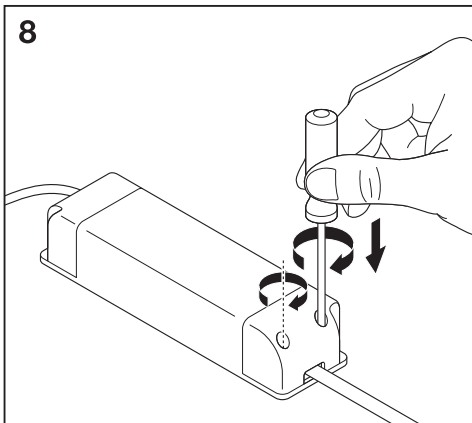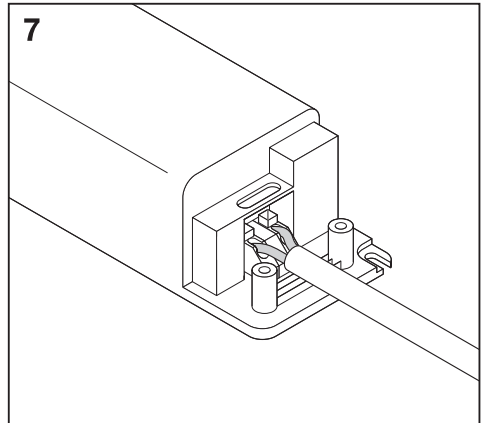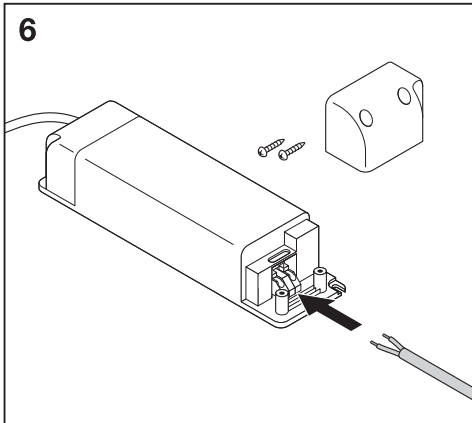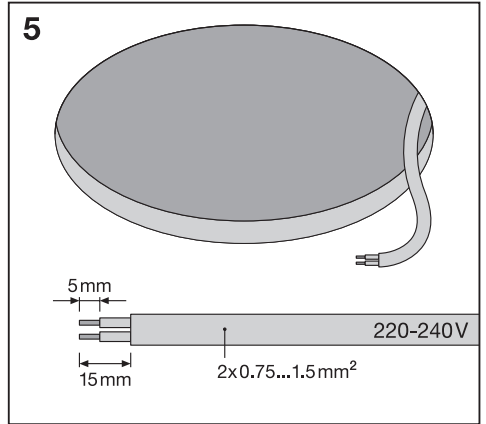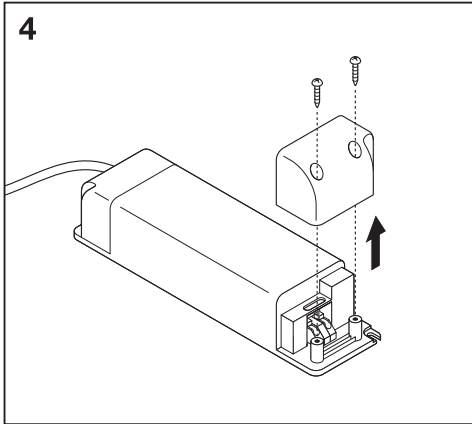

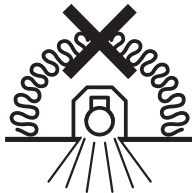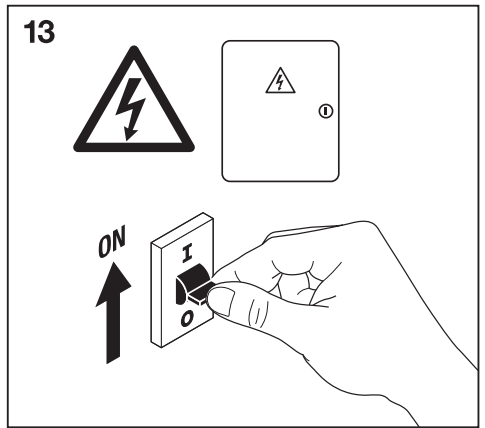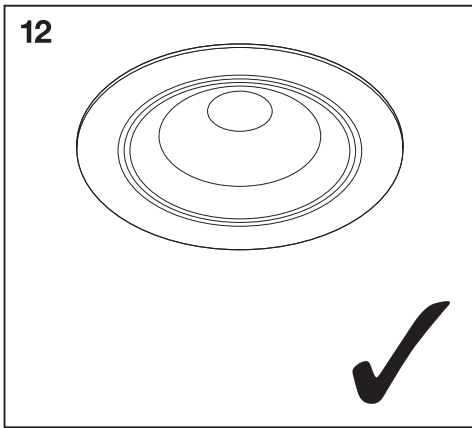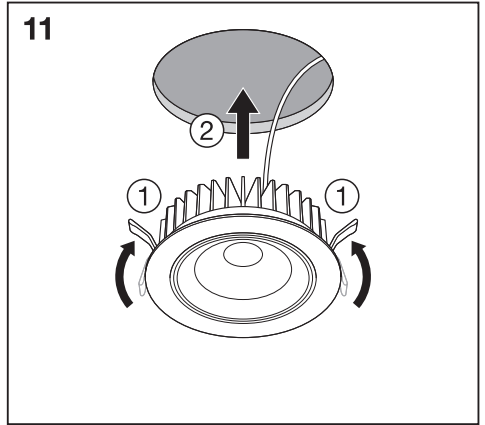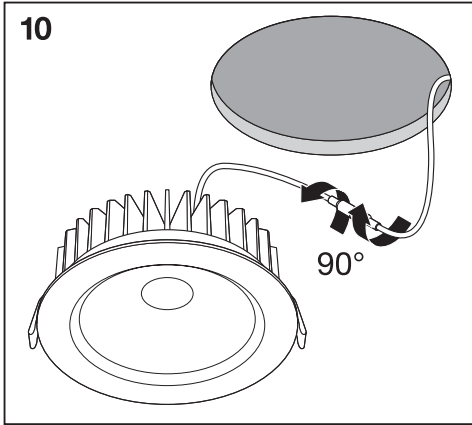

RoHS



C10449057
G11034658
10.01.18



LEDVANCE GmbH
Steinerne Furt 62
86167 Augsburg, Germany
www.ledvance.com