


ISO 7379

Passschulterrauben

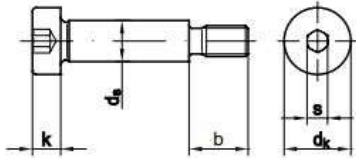

*Passschafttoleranz:

- Stahl h8 oder f9
- Edelstahl f9

**Lagervorrat Ø12, Normwert Ø13

***nicht genormte Abmessung

Maße	M 5	M 6	M 8
d_k	10	13	16
d_s^*	6***	8	10
k	4,5	5,5	7
s	3	4	5
b	9,75	11,25	13,25

Maße	M 10	M 12	M 16
d_k	18	24	30
d_s^*	12**/13	16	20
k	9	11	14
s	6	8	10
b	16,4	18,4	22,4