


ASUS PA34VC



EAN:
4718017030250
Produkt Nummer:
90LM04A0-B01370

Highlights

- 86,61cm (34,1 Zoll) UWQHD 1900R IPS-Monitor mit rahmenlosem Design
- 100% sRGB-Farbraumabdeckung, ab Werk vorkalibriert für eine hervorragende Farbtreue
- Die HDR-10-Kompatibilität ermöglicht eine besonders dynamische und realistische Bildarstellung
- Thunderbolt 3 USB-C für Datenübertragungsraten von bis zu 40Gbit/s und Power Delivery mit bis zu 60W Leistung für externe Geräte
- ASUS ProArt – Kalibrierungstechnologie bietet eine 14-Bit Look-Up-Tabelle (LUT), Uniformitätskompensation und die Möglichkeit, Farbprofile auf dem Monitor zu speichern

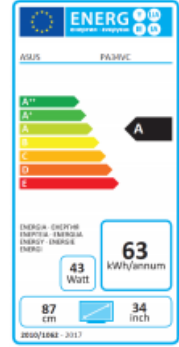

Spezifikationen

Bildschirm	Panel Size: Wide Screen 34" (86.72cm) 21:9 Color Saturation : 100%(sRGB) Panel Type : IPS True Resolution : 3440x1440 Display Viewing Area(HxV) : 799.8 x 334.8 mm Display Surface : Non-glare Pixel Pitch : 0.2325 mm Brightness : 300 cd/? (Typical) Contrast Ratio : 1000 :1 (Typical) Viewing Angle (CR?10) : 178°(H)/178°(V) Response Time : 5ms (Gray to Gray) Display Colors : 1073.7M (10bit) Flicker free LCD ZBD Warranty : Yes Curved Panel : 1900R HDR (High Dynamic Range) Support : Yes Refresh Rate(max) : 100Hz
Video-Features	Trace Free Technology : Yes SPLENDID Video Preset Modes : 9 Modes (HDR/sRGB Mode/Rec. 709 Mode/Scenery Mode/Standard Mode/User Mode 1/User Mode 2/Reading Mode/Darkroom Mode) Color Temperature Selection : 4 Modes Color Accuracy : ?E Gamma adjustment : Yes (Support Gamma 1.8/2.0/2.2/2.4/2.6) Color Adjustment : 6-axis adjustment(R,G,B,C,M,Y) Picture-in-Picture : Yes Picture-by-Picture : Yes Low Blue Light : Yes HDCP support : Yes, 1.4 & 2.2 VividPixel : Yes Adaptive-Sync supported :Yes HDR (High Dynamic Range) Support :Yes HDR-10
Audio-Features	Stereo Speakers : 2W x 2 Stereo RMS
E/A-Schnittstellen	Signal Input : Thunderbolt™ 3 USB-C™ x2 (In x1, Out x1), HDMI(v2.0b) x2, DisplayPort Earphone jack : 3.5mm Mini-Jack USB upstream : Thunderbolt™ 3 USB-C™ x2 USB downstream : USB3.0 Type-A x3
Signalfrequenz	Digital Signal Frequency : 30 ~151 KHz (H) /40 ~100 Hz(V)
Stromverbrauch	Power On (Typical); Power Saving Mode : 100-240V, 50/60Hz
Gehäusedesign	Chassis Colors : Black Tilt : +23°--5° Swivel : +30°--30° Height Adjustment : 0~120 mm VESA Wall Mounting : 100x100mm Quick Release Stand Design : Yes
Sicherheitsfeatures	Kensington lock
Abmessungen	Phys. Dimension with Stand (WxHxD) : 815.12 x (418~538) x 222.86 mm Phys. Dimension without Stand (WxHxD) : 815.12 x 364.79 x 122.17 mmBox Dimension (WxHxD) : 980 x 401 x 588 mm

Gewicht	Net Weight (Esti.) : 11.4 kg, Without Stand: 7.8 Kg, Gross Weight (Esti.) : 17.18 kg
Zubehör	Thunderbolt™ 3 Cable Power cord DisplayPort cable USB-C to A cable Quick start guide HDMI cable Support CD Warranty Card Color pre-calibration report
Regulierungsabnahme	BSMI, CB, CCC, CE, CEL level 0, CU, ErP, FCC, ISO-9241-307, J-MOSS, Mac Compliance, PSE, RoHS, UL/cUL, VCCI, WEEE, WHQL (Windows 10, Windows 8.1, Windows 7), RCM, TUV Flicker-free , Ukraine , KC , eStandby, TUV Low Blue Light, Vietnam MEPS, MSIP(KCC), EU energy label
Anmerkung	*measuring a screen brightness of 200 nits without audio / USB / Card reader connection **All specifications are subject to change without notice.
