

Elektrische Werte

*Bemessungsstrom	max. 3 A
Durchgangswiderstand	< 5 mOhm

Werkstoff

Kontakt	Federbronze, aktiver Bereich vergoldet
---------	---

Anschluß


Anschlußart	crimp
Anschlußbereich	0,08 - 0,20mm ²
max. Litzenaußendurchmesser	ø1,3 mm
Abisolierlänge	2,7 mm

Mechanische Werte

Steckzyklen	500
-------------	-----

Werkzeuge (nicht im Lieferumfang enthalten)

Handcrimpzange	C0.078.00
Crimpmaschine	WA10043
Crimpeinsatz für Maschine	WM10242

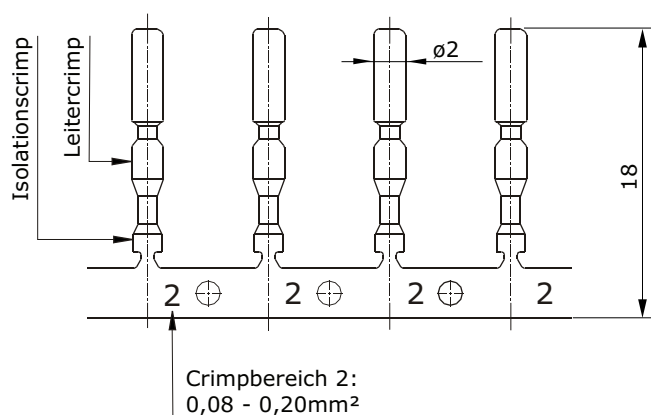

Hauptabmessungen

Kontaktbuchsen

Bandoleer Contact 1mm Socket

for :623 Insulation Insert 12/17-pin

order code: 60.199.80

Electrical Data

*nominal current max 3A
contact resistance < 5 mOhm

Material

Contact phosphorus bronze,
active area, gold plated

Termination


kind of termination crimp
cross section 0,08 - 0,20 mm²
max. outer diameter ø1,3 mm
stripping length 2,7 mm

Mechanical Data

mating cycles 500

Tools (not included in delivery)

Crimping tool order code: C0.078.00
crimping machine order code: WA10043
crimping insert for machine order code: WM10242

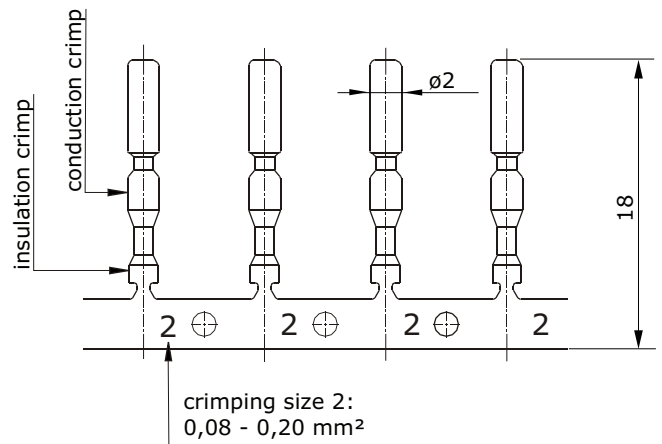

Main Dimensions
contact socket

Copyright by INTERCONTEC Produkt GmbH, Germany.
All rights reserved in case of a patent or GM registration.
Violation will result in a claim for damages.
All data is just for information. Before utilization of the stated information
And data the user has to reassure the validity and topicality.
Specifications are subject to change without notice.

INTERCONTEC Produkt GmbH
Bernrieder Str. 15, 94559 Niederwinkling
Tel.: 0049 9962/ 2002-0, Fax: 0049 9962/ 2002-70
E-Mail: info@intercontec.biz
Web: www.intercontec.biz

* for max. wire cross-section