



Einsatzbereich:
923 - Einbaudosen
Winkeleinbaudose

Best.-Nr.: 61.194.11

Elektrische Werte

*Bemessungsstrom max. 3 A
Durchgangswiderstand < 3 mOhm

Werkstoff

Kontakt Messing, vergoldet

Anschluß



Anschlußart crimp
Anschlußbereich 0,10 - 0,5 mm²
Abisolierlänge 7 mm

Mechanische Werte

Steckzyklen 500

Werkzeuge (nicht im Lieferumfang enthalten)

 digitale Crimpzange Best Nr.: C0.236.00
(analoge Crimpzange Best Nr.: C0.201.00
Positioniereinsatz für 2mm Kontakte Best Nr.: C0.004.00)

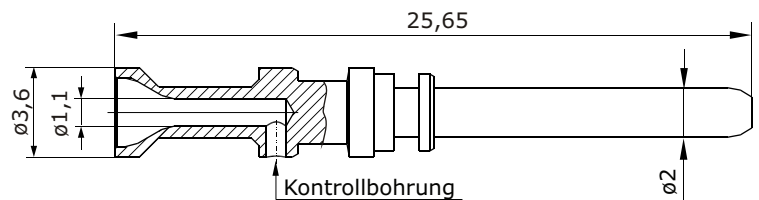

Hauptabmessungen

Kontaktstift



for:
**923 - Receptacle
Receptacle Angled**

order code: 61.194.11

Electrical Data

*rated current max. 3 A
contact resistance < 3 mOhm

Material

contact brass, gold plated

Termination


 
kind of termination crimp
cross section 0.10 - 0.50mm²
stripping length 7 mm

Mechanical Data

mating cycles 500

Tools (not part of product contents)

digital crimping tool order code: C0.236.00
(analog crimping tool order code: C0.201.00
positioning insert for 2mm contacts order code: C0.004.00)

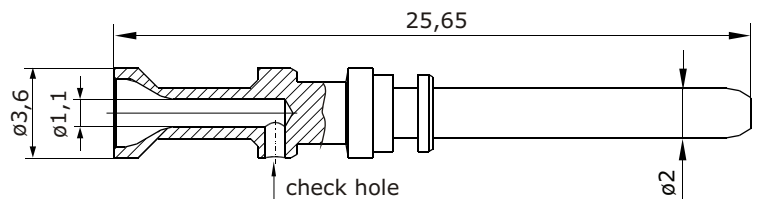

Main Dimensions

contact pin