



LITHIUM COIN CELL CR 2320

- Reliable energy for your application
- Standard cells and customized packs
- ESD protection
- UL recognized
- Battery Certification Experts



RoHS compliant



Pb free



REACH
compliant




Conflict
mineral free

SPECIFICATIONS

Nominal Voltage	3V
Jauch part number	249998 (1pc blister)
Nominal Capacity	155 mAh
Standard Load	15 kΩ
Standard Current	0.2 mA
Max. Continuous Current	3 mA
Max. Pulse Current	18 mA
Operating Temperature	-20°C to +60°C*
Weight	2.65 gr
Chemistry	Li/MnO ₂
UL1642	MH62838


* In applications where the battery is exposed to temperatures >60°C, please contact Jauch.

DIMENSIONS

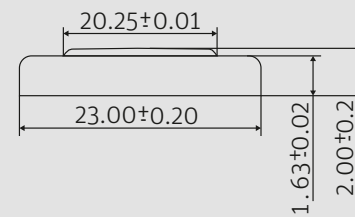


Available Terminals and Wire Connectors: please contact Jauch for diagram of batteries with terminals (batterytechnology@jauch.com).


DISCHARGE CHARACTERISTICS

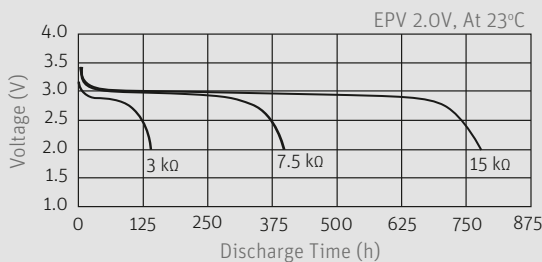

TEMPERATURE CHARACTERISTICS

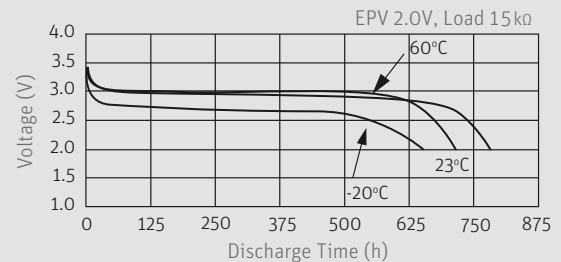

PULSE DISCHARGE CHARACTERISTICS

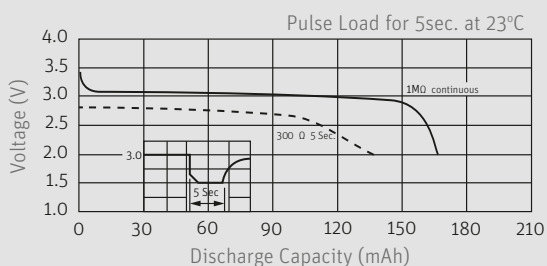

LOAD VS: CAPACITY

