



LITHIUM COIN CELL CR 1616

- Reliable energy for your application
- Standard cells and customized packs
- ESD protection
- UL recognized
- Battery Certification Experts



RoHS compliant



Pb free



REACH compliant




Conflict mineral free

SPECIFICATIONS

Nominal Voltage	3V
Jauch part number	250009 (1pc blister)
Nominal Capacity	55 mAh
Standard Load	30 kΩ
Standard Current	0.1 mA
Max. Continuous Current	0.65 mA
Max. Pulse Current	8 mA
Operating Temperature	-20°C to +60°C*
Weight	1.10 gr
Chemistry	Li/MnO ₂
UL1642	MH62838


* In applications where the battery is exposed to temperatures >60°C, please contact Jauch.

DIMENSIONS

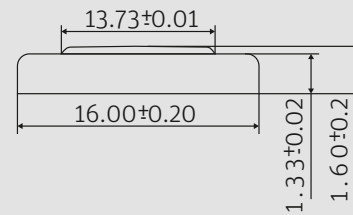


Available Terminals and Wire Connectors: please contact Jauch for diagram of batteries with terminals (batterytechnology@jauch.com).


DISCHARGE CHARACTERISTICS

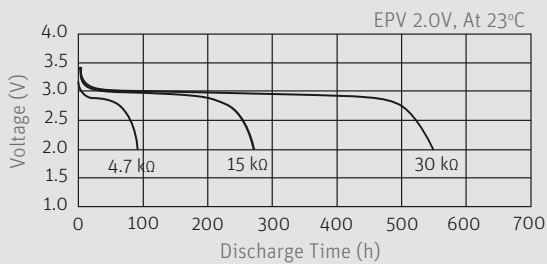

TEMPERATURE CHARACTERISTICS

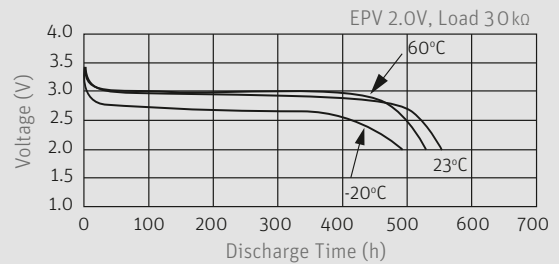

PULSE DISCHARGE CHARACTERISTICS

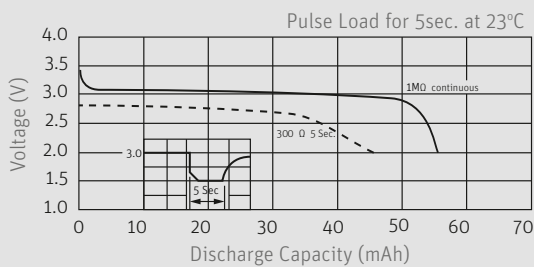

LOAD VS: CAPACITY

