



Lithium Coin Cell - CR 1025

- Reliable energy for your application
- Standard cells and customized packs
- ESD protection
- UL recognized
- Battery Certification Experts



RoHS compliant



Pb free



REACH compliant



Conflict mineral free


Technical Data Sheet · CR 1025

SPECIFICATIONS


Nominal Voltage	3V
Jauch part number	247980
Nominal Capacity	30 mAh
Standard Load	68 kΩ
Standard Current	0.05 mA
Max. Continuous Current	< 0.1 mA
Max. Pulse Current	5 mA
Operating Temperature	-30°C to +70°C*
Weight	Approx. 0.55 gr.
Chemistry	Li/MnO ₂
UI1642	MH62838

* In applications where the battery is exposed to temperatures >60°C, please contact Jauch.


DIMENSIONS

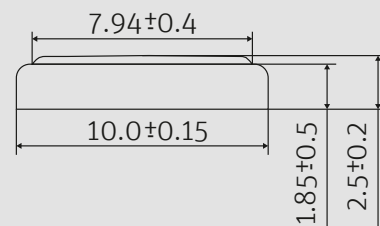


DISCHARGE CHARACTERISTICS

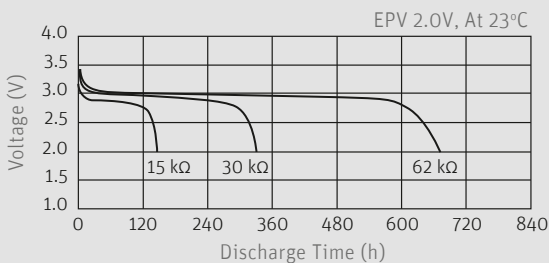


TEMPERATURE CHARACTERISTICS

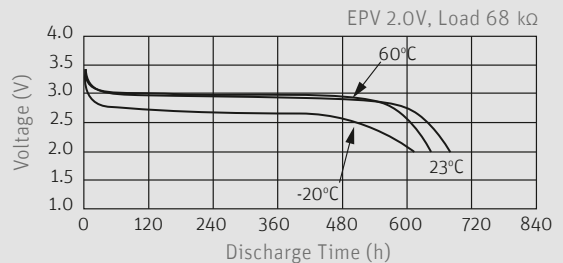

PULSE DISCHARGE CHARACTERISTICS

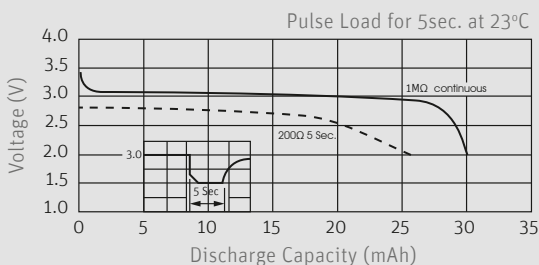

LOAD VS: CAPACITY

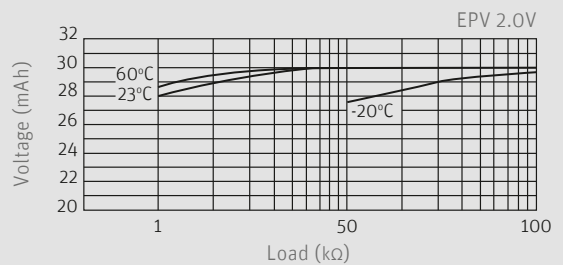

Wide assortment of mounting options, including through hole, surface mount and wire terminals.

Contact Jauch for more information
batterytechnology@jauch.com