

Artikel Nr.: 731011

Wandaufbauleuchte, Zilly II Up and Down Motion, silberfarben, 220-240V AC/50-60Hz, 2x max. 35,00W

Technische Daten

Charakteristik

Material	Edelstahl
Farbe	silberfarben
Optik	
im Lieferumfang	Bewegungsmelder-/Dämmerungsschalter



Elektrische Daten

Leistung	2x max. 35,00 W
Eingangsspannung	220-240V AC/50-60Hz
Eingangsstrom	
Fassung / Sockel	GU10
Anzahl Sockel	2
Netzgerät	
Anschlussmöglichkeit	Klemme
Schutzklasse I, II, III	I




Artikel Nr.: 731011

Wandaufbauleuchte, Zilly II Up and Down Motion, silberfarben, 220-240V AC/50-60Hz, 2x max. 35,00W

Lichtrichtung

Dreh- und Schwenkbereich	feststehend
Neigungswinkel	
Abstrahlverhalten	2 Side
Reflektor / Linse	symmetrisch

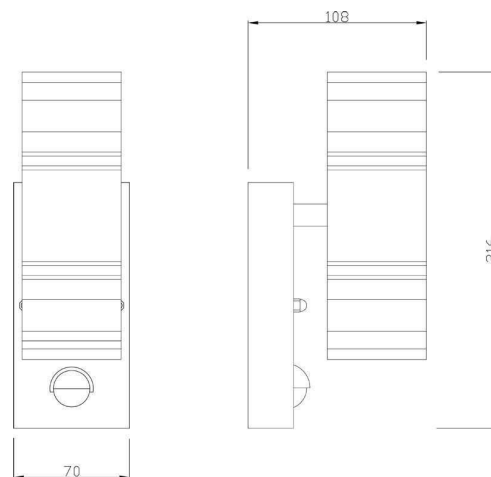

Abmessungen und Gewicht

Länge	220,00
Breite	70,00
Höhe	108,00
Durchmesser	60,00
Gewicht	1086 g

Grenzwerte

Betriebstemperatur	-20°C - +50°C
Lagertemperatur	-10°C - +60°C
IP - Schutzart	IP44

EEL Die Leuchte ist geeignet für Leuchtmittel der Energieeffizienzklassen A++ bis E

IP44 Schutz gegen das Eindringen von Fremdkörper > 1 mm. Geschützt gegen Spritzwasser.



Leuchte der Schutzklasse I bei der der Schutz gegen elektrischen Schlag nicht allein auf der Basisisolierung beruht, sondern die eine zusätzliche Sicherheitsvorkehrung derart enthält, dass berührbare leitfähige Teile mit Mitteln zum Anschluss an den Schutzleiter der festen Installation ausgerüstet sind, so dass im Fehlerfall der Basisisolierung berührbare leitfähige Teile nicht aktiv werden können.



Aufgrund des komplexen Herstellungsprozesses von LED stellen die angegebenen Werte nur rein statistische Größen dar und müssen nicht zwingend den tatsächlichen Parametern jedes einzelnen LED-Moduls entsprechen, sondern können von den typischen Werten abweichen.

Article no.: 731011

Surface mounted wall lamp, Zilly II Up and Down Motion, silver, 220-240V AC/50-60Hz, 2x max. 35,00 W

Technical Data**General Characteristics**

Material	stainless steel
Colour	silver
Optics	
included in delivery	twilight- /motion switch

**Electrical Characteristics**


Power	2x max. 35,00 W
Input Voltage	220-240V AC/50-60Hz
Input current	
Base (standard designation)	GU10
Number of Bases	2
Power supply unit	
Connection possibility	clamp
Protection class I, II, III	I

Article no.: 731011

Surface mounted wall lamp, Zilly II Up and Down Motion, silver, 220-240V AC/50-60Hz, 2x max. 35,00 W

Light Direction

Rotating and tilting range	fixed
Angle of inclination	
Radiation direction	2 Side
Reflector / lense	symmetrisch

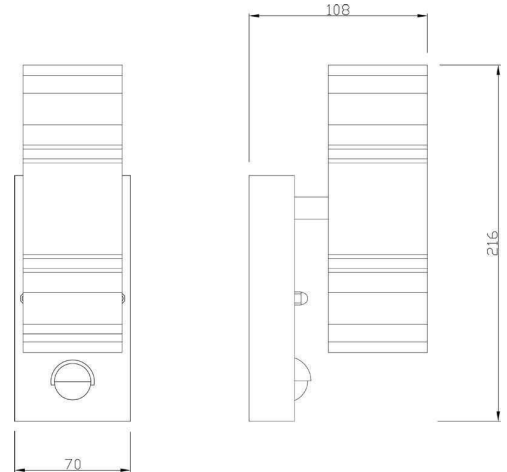

Dimensions & Weight

Length	220,00
Width	70,00
Height	108,00
Diameter	60,00
Product Weight	1086 g

Absolute maximum ratings

Working temperature	-20°C - +50°C
Storage temperature	-10°C - +60°C
IP - Code	IP44

EEL The luminaire is suitable for lamps of energy efficiency classes A++ to E.

IP44 Protection against penetration of foreign objects > 1 mm. Protection against penetration of splashing water.



Lightings of Protection Class I in which the protection against electric shock is not based solely on isolation, but an additional safety measure contains such a way that accessible conductive parts are equipped with means for connection to the protective conductor of the fixed installation, so that in case of failure of the basic insulation exposed conductive parts cannot be active.



Because of the complex manufacturing process of the LED the above shown data are just a statistical size, which is not forced to be the realistic data of every LED.