


Instruction Manual | Bedienungsanleitung | Manual de instrucciones | Manuale d'istruzioni | Manuel d'instructions | Handleiding | Návod k použití

www.megaman.cc/resources/document-library/user-guides

FTK70317v0 / MM78800, MM78840, MM78850

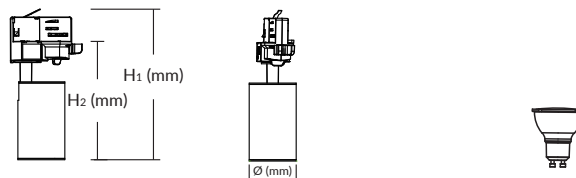

FTK70317v0 MM78800, MM78840, MM78850	H <sub>1</sub> 180	H <sub>2</sub> 144	Ø60	Max. 8W MEGAMAN® LED GU10
---	--------------------	--------------------	-----	---------------------------

### Correct disposal of this product

This marking indicates that this product should not be disposed with other household wastes throughout the EU. To prevent possible harm to the environment or human health from uncontrolled waste disposal, recycle it responsibly to promote the sustainable reuse of material resources. To return your used device, please use the return and collection systems or contact the retailer where the product was purchased. They can take this product for environmental safe recycling.

IDV GmbH  
Birkenweiherstr. 2  
D-63505 Langenselbold  
Germany  
www.megaman.de

### Die korrekte Entsorgung des Produkts

Produkte, die mit diesem Symbol gekennzeichnet sind, gehören nicht in den Hausmüll, sondern müssen in Übereinstimmung mit der WEEE-Richtlinie entsorgt werden. Private Haushalte können verbrauchte Leuchten sowie Energiesparlampen und LED-Lampen kostenlos bei den Wertstoffhöfen bzw. Sammelstellen ihrer Kommune oder im Handel abgeben (in Deutschland, Österreich: freiwillige Rücknahmestellen). Gewerbliche Anwender können die Leuchten und Lampen kostenlos bei registrierten Sammelstellen anliefern.

220-240V~ 50/60 Hz  $t_a$  -30°C ~ +40°C IP20