











Imou




Rex 3D 5MP

5MP H.265 Wi-Fi Pan & Tilt Camera

With 5MP/3K live monitoring and panoramic pan & tilt feature, Rex 3D ensures every corner of your home completely covered. Human/Pet Detection quickly finds human/pet targets in the images and sends a notification to you. With built-in siren, Rex 3D actively keeps unwelcome visitors away from what you care about. Privacy Mode helps protect your personal privacy when you are home, and Smart Tracking function lets the camera follow moving objects when it detects motion.

- | | | |
|--|---|---|
|  H.265 5MP/3K
Sees more than 1080P |  AI Smart Detection
Quickly finds human/pet targets in your home |  Smart Tracking
Automatically tracks moving objects |
|  Privacy Mode
Hides the lens to protect your personal privacy |  Active Deterrence
Scare away unwelcome visitors with built-in siren. Customizable Alarm Ringtone. |  Two-way Talk
Real-time communicates with people at the camera |
|  24/7 Protection
Infrared night vision for clear-as-day clarity even in pitch dark |  Abnormal Sound Alarm
Sends alerts to your smartphone when it detects abnormal sound |  Auto-cruise
Survey the area 360° horizontally or cruise between favorite points |
|  Diversified Storage
Supports NVR, Cloud Storage or Micro SD card (up to 256GB) |  Alarm Notification
Sends instant motion-activated alerts to your mobile phone |  Wi-Fi Connection
IEEE802.11b/g/n(2.4GHz) |

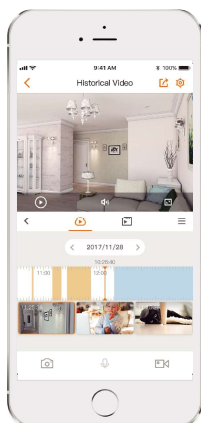

Stay close with what you care

With Cloud service, you will have access to what you care as long as Internet is available. You can record daily or motion videos on Cloud and play back anytime anywhere.

<http://www.imoulife.com>



Front View



Back View

Specifications

Camera

1/3" Progressive CMOS
5MP(2688 x 1620)
Night Vision: 10m(33ft) Distance
3.6mm Fixed Lens
Field of View : 77° (H), 40° (V), 91° (D)
0~355° Pan & 0~90° Tilt

Video & Audio

Video Compression : H.265/H.264
Up to 25/30fps Frame Rate
Digital Zoom
Two-way Audio

Notice Management

Motion Detection
Human Detection
Pet Detection
Configurable Region
Abnormal Sound Alarm

Network

1 x 100Mbps Ethernet Port
Wi-Fi:IEEE802.11b/g/n, 50m Open Field
Imou App: iOS, Android
Onvif

Auxiliary Interface

Micro SD Card Slot (up to 256GB)
Built-in Mic & Speaker
Reset Button

General

DC 5V1A Power Supply
Power Consumption:<5W
Working Environment:-10° C~+45° C, Less Than 95%RH
Dimensions: 90 × 90 × 107.4mm (3.5 × 3.5 × 4.3inch)
Weight: 206g (0.45lb)
CE

What's in the box

- 1x Camera
- 1x Quick Start Guide
- 1x Power Adapter
- 1x USB Cable
- 1x Screw Package
- 1x Quick Installation Board
- 1x Installation Position Map

