




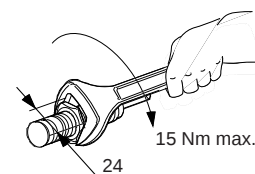

Osiris XU5-M18U1D

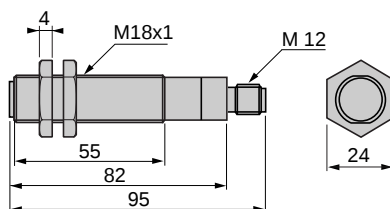


Luminescence detector / Détecteur de luminescence / Lumineszenzdetektor / Detector de luminiscencia / Sensore di luminescenza / Detector de luminescência

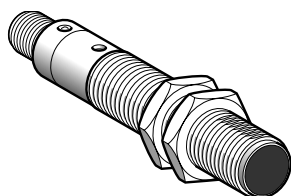


Max.tightening torque /
Couple de serrage maxi. /
Anzugsmoment maxi /
Par de apriete máximo /
Coppia di serraggio massima /
Binário máximo de aperto


Mechanical installation / Mise en œuvre mécanique / Mechanische Installation / Instalación mecánica / Messa in opera meccanica / Instalação mecânica

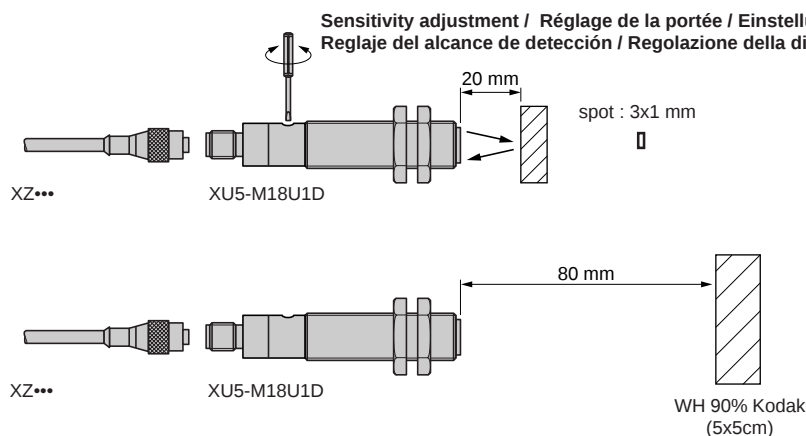



Setting-up / Zone de détection / Erfassungsbereich / Zona de detección / Messa in opera / Curvas de detecção

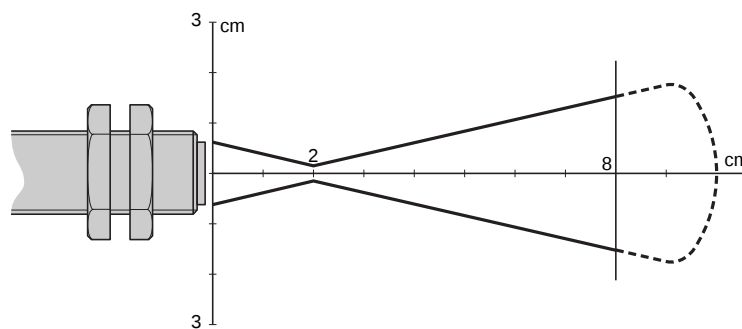

Electrical installation / Mise en œuvre électrique / Elektrische Installation / Instalación eléctrica / Messa in opera elettrica / Instalação eléctrica

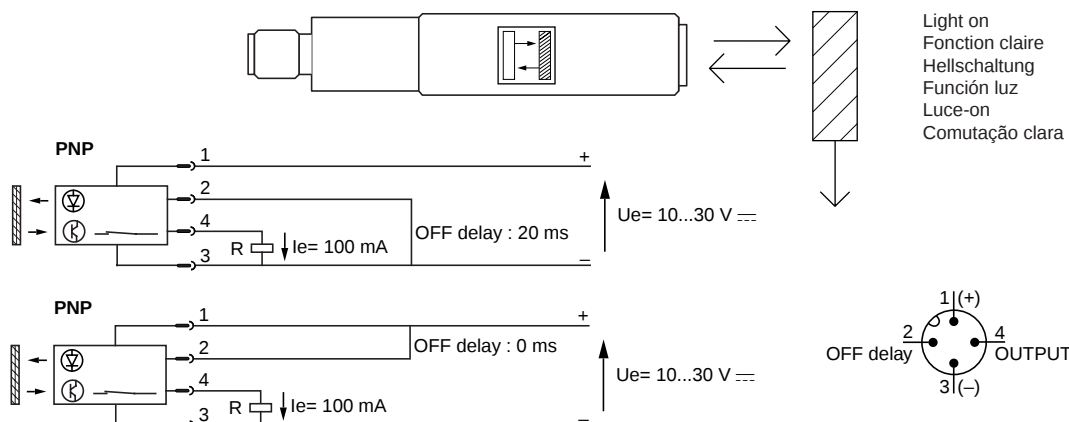

Indication / signalisation / Funktionsanzeige / Señalización / segnalazione / sinalização

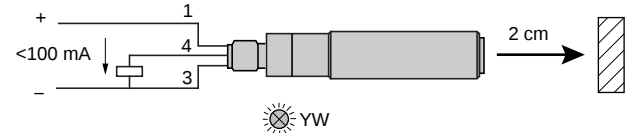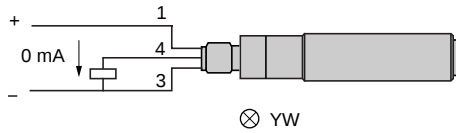

YW

Yellow

Jaune

 

 


Gerb

Amarillo

Giallo



Amarelo

Installation precautions / Précautions de mise en œuvre / Vorsicht bei der Inbetriebnahme / Precauciones para la instalación / Consigli di messa in opera / Precaução de instalação

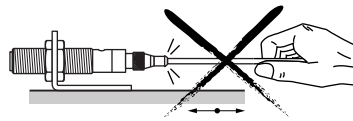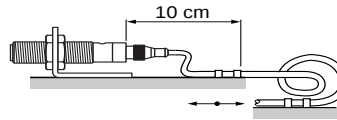
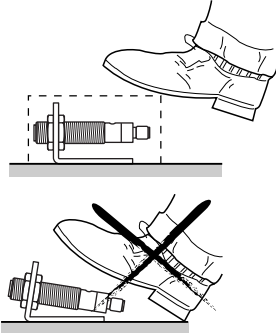


Fixing accessories / Accessoires de fixation / Befestigungszubehör / Accesorios de fijación / Accessori di fissaggio / Acessórios de fixação



XSA-Z118

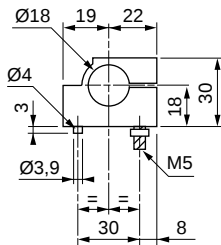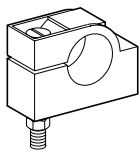



XSZ-B118

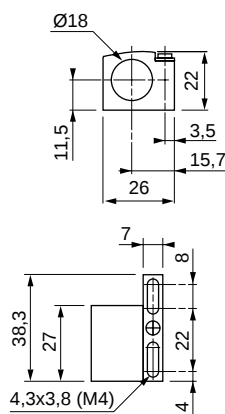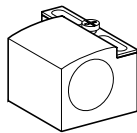


XUZ-A118

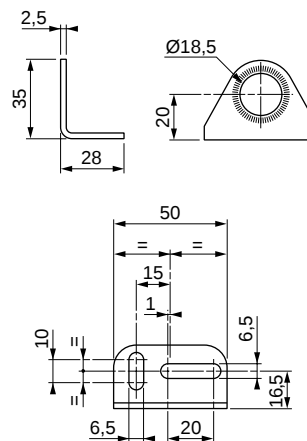 



XUZ-A218

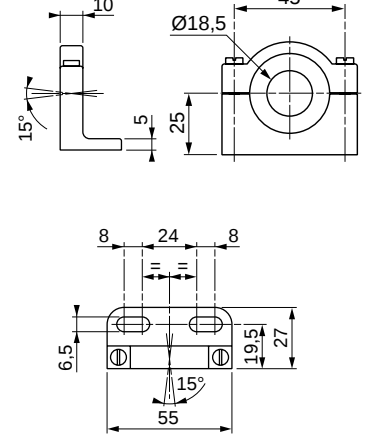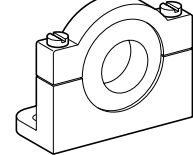

Machine cabling accessories / Constituants de câblage machines / Zuberh r f r Maschinen-Anschlu stechnik / Constituyentes de conexi nado / Accessori di cablaggio / Constituintes de cablagem

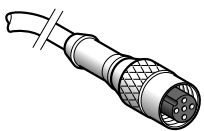


 XZC-P1141L2 (2m)
XZC-P1141L5 (5m)
XZC-P1141L10 (10m)

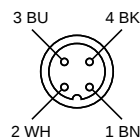


XZC-P1241L2 (2m)
XZC-P1241L5 (5m)
XZC-P1241L10 (10m)

XZC-P1340L
XZC-P1440L

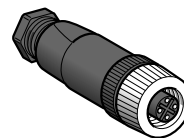

XZC-C12FDM40B metal (9)
XZC-C12FDP40B plastic (10)

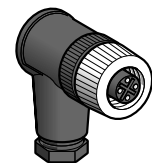

XZC-C12FCM40B metal (1)
XZC-C12FCP40B plastic (2)

With screw terminals Number of wires and c.s.a. : 4 x 0,75 mm²
Raccordement par bornier Capacit  : 4 x 0,75 mm²
Anschlu  : Schraubanschl  klemmen 4 x 0,75 mm²
Conexi n por bornas con tornillos, capacidad : 4 x 0,75 mm²
Collegamento su morsettiere a vite, capacit  : 4 x 0,75 mm²
Liga o por terminais com parafusos, capacidade : 4 x 0,75 mm²



Listing and



Certification :

Applicable on proximity switches
bearing the UL and CSA marks only
Enclosure : Type 12,4X indoor use only.