



Installation precautions / Précautions de mise en œuvre / Vorsicht bei der Inbetriebnahme / Precauciones para la instalación / Consigli di messa in opera / Precaução de instalação

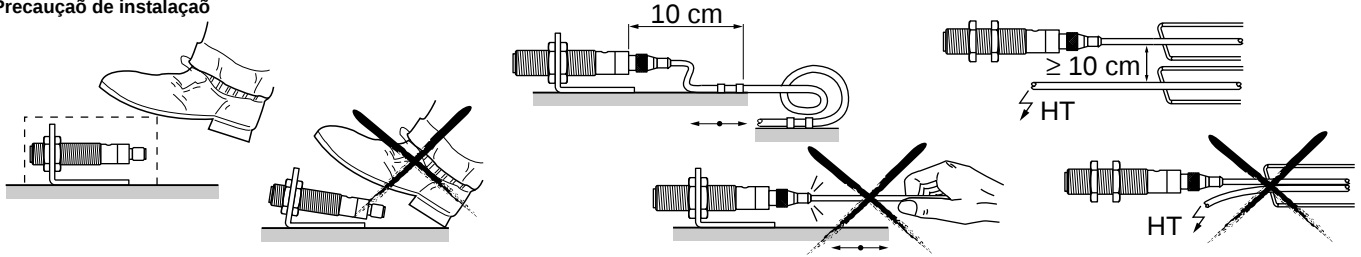


Fixing accessories / Accessoires de fixation / Befestigungszubehör / Accesorios de fijación / Accessori di fissaggio / Acessórios de fixação

XSA-Z118

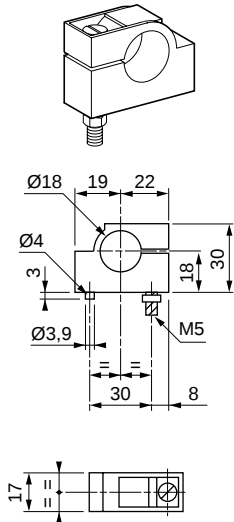


XSZ-B118

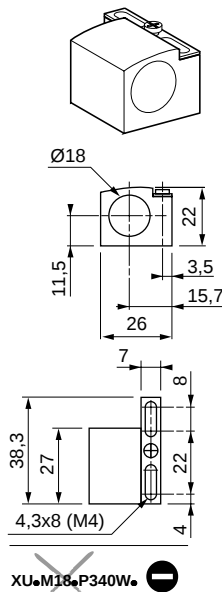


XU●M18●P340W●


XUZ-A118

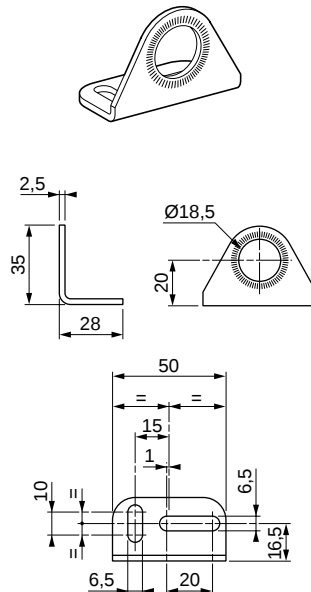



XUZ-A218

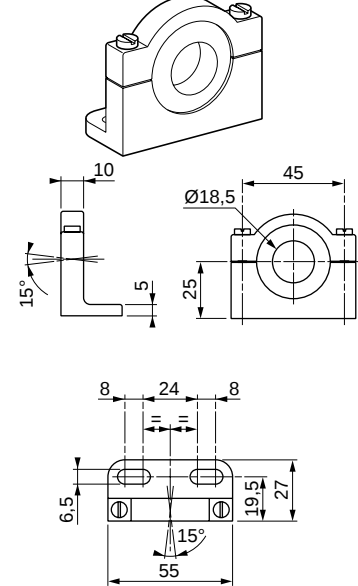

Machine cabling accessories / Constituants de câblage machines / Zuberhör für Maschinen-Anschlußtechnik / Constituyentes de conexianado / Accessori di cablaggio / Constituintes de cablagem

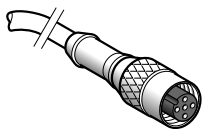


 XZC-P1141L2 (2m)
XZC-P1141L5 (5m)
XZC-P1141L10 (10m)

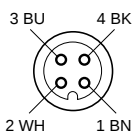

XZC-P1241L2 (2m)
XZC-P1241L5 (5m)
XZC-P1241L10 (10m)

XZC-P1340L●
XZC-P1440L●

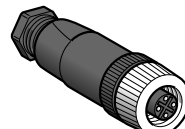


XZC-C12FDM40B metal (4)
XZC-C12FDP40B plastic (5)






XZC-C12FCM40B metal (4)
XZC-C12FCP40B plastic (5)

With screw terminals Number of wires and c.s.a. : 4 x 0,75 mm²
Raccordement par bornier Capacité : 4 x 0,75 mm²
Anschluß : Schraubanschlußklemmen 4 x 0,75 mm²
Conexión por bornas con tornillos, capacidad : 4 x 0,75 mm²
Collegamento su morsettiere a vite, capacità : 4 x 0,75 mm²
Ligação por terminais com parafusos, capacidade : 4 x 0,75 mm²


 
Reflector / Réflecteur / Reflektor / Reflector / Catarifrangente / Reflector



XUZ-C24

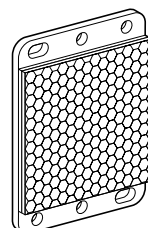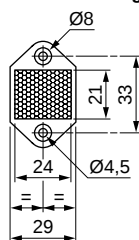 

XUZ-C50

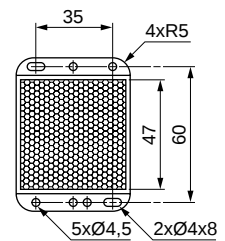 

- (1) Fonction claire / Hellschaltung / Función luz / Luce-on / Comutação clara
- (2) Programmation clair-sombre / Programmierung Hell-Dunkel / Programación luz-sombra / Programmazione chiaro-buio / Programação clara-sombra.
- (3) Ø du faisceau / Ø Lichtstrahl / Ø del haz / Ø del fascio / Ø do feixe.
- (4) métal / metall / metálico / metallica / metálica
- (5) plastique / Kunststoff / plástico / plastica / plástico

UL and CE Approvals :

Applicable on proximity switches bearing the UL and CSA Listing marks only
Enclosure : Type 12,4X indoor use only.



Osiris XU●-P18 / XU●-N18



Telemecanique

Photo-electric sensor M18, d.c. supply, solid state output


Détecteur photoélectrique M18, alimentation en courant continu, sortie statique

Photoelektronische Sensoren M18, Geräte für Gleichspannung, Ausgang : statisch


Detectores fotoeléctricos M18, alimentación en corriente continua, salida estática

Interruttori fotoelettrici M18, alimentazione in corrente continua, uscita statica


Detectores foto-eléctricos M18, alimentação em corrente contínua, saída estática

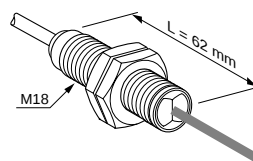


XU●-18-P34●

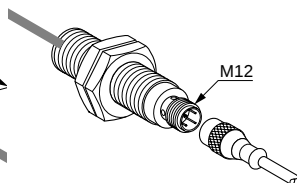

XU●-18-P34●D

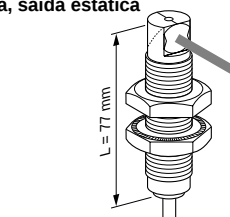


XU●-18-P34●W

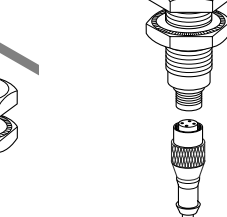

XU●-18-P34●WD

Max.tightening torque /
Couple de serrage maxi. /
Anzugsmoment maxi /
Par de apriete máximo /
Coppia di serraggio massima /
Binário máximo de aperto

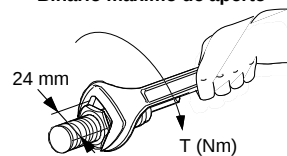


XU●N18 : T = 15 Nm


XU●P18 : T = 5 Nm

Electrical installation / Mise en œuvre électrique / Elektrische Installation / Instalación eléctrica / Messa in opera elettrica / Instalação eléctrica


Light on (1)

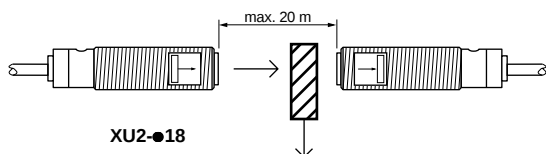


XU2-18

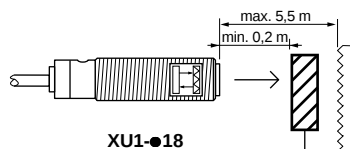

XU1-18









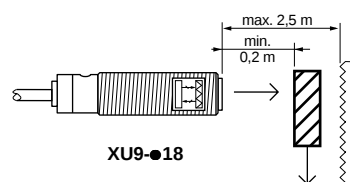


XU9-18

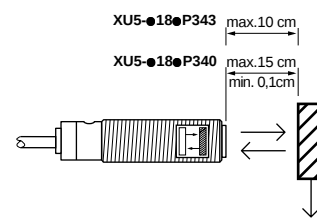


XU5-18-P343

 
XU5-18-P340

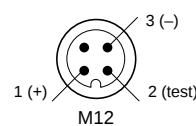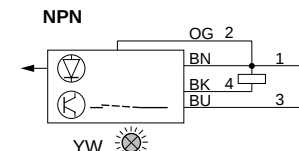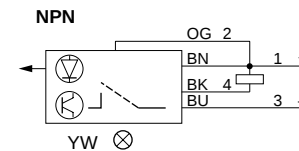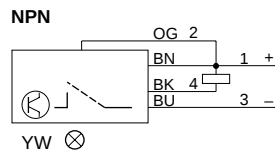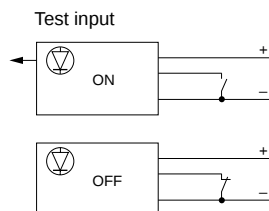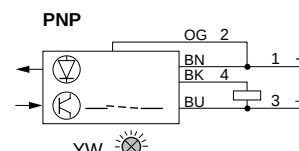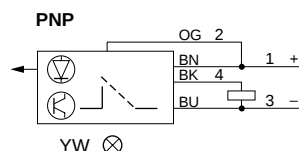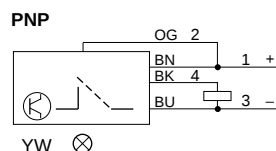


M12

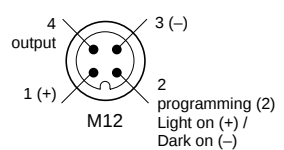


M12

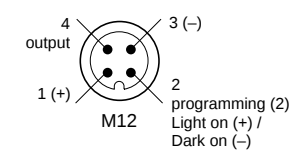


M12

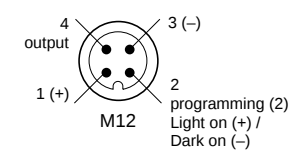


M12

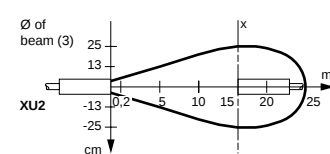


XU2

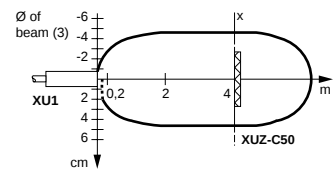

XU1

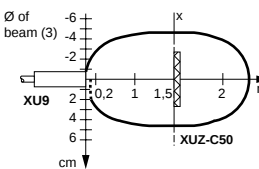

XU9

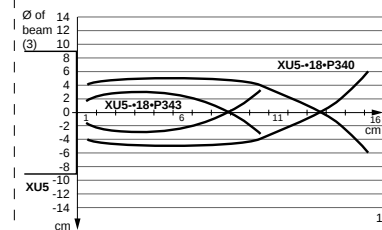

XU5

	YW	Yellow	Jaune	Gerb	Amarillo	Giallo	Amarelo
	BN	Brown	Brun	Brau	Marrón	Marrone	Castanho
	BU	Blue	Bleu	Blau	Azul	Azul	Azul
	BK	Black	Noir	Schwarz	Negro	Nero	Preto
	OG	Orange	Orange	Orange	Naranja	Arancio	Laranja
	WH	White	Blanc	Weiß	Blanco	Bianco	Branco
	VI	Violet	Violet	Violett	Violeta	Viola	Violeta

Voltage limits / limites de tension / Betriebsspannung / Límites de tensión / Limiti di tensione / Limite de tensão	10...30 V $\overline{\text{DC}}$
Load switching capacity / Courant commuté / Schaltstrom / Intensidad conmutada / Corrente commutata / Corrente comutada	≤ 100 mA
Current consumption / Puissance consommée / Leistung / Potencias consumida / Potenza consumata / Potencia consumida	≤ 30 mA (XU1/5/9) ≤ 50 mA (XU2)
Maximum switching frequency / Fréquence maxi de commutation / Maximale Schaltfrequenz f / Frecuencia máxima de commutación / Frecuencia di commutazione max. / Frequência máxima de comutação	500 Hz