

LED Maschinenleuchte




LED machine light



TUBELED_25, Länge 205 mm, kaskadierbar

Artikel-Nr.:	154010-02
EAN:	4260556625898

Bestell-Nr.:	154010-02
Modell:	TUBELED_25
Bauform:	LED Aufbauleuchte für Maschinen und Anlagen
Leuchtmittel:	SMD LED
Lampenleistung:	~4,3 W
Lampenlichtstrom:	667 lm
Lampenlichtausbeute:	155 lm/W
Lichtverteilung:	direkt
Lichtfarbe:	Tageslichtweiß (5200 - 5700K)
Anschlusswert Leuchte:	24V DC ± 10%
Anschluss Leuchte:	M8 A-kodiert
Schutzart:	IP67
Schutzklasse:	III
Entblendung:	Einscheiben-Sicherheitsglas diffus
Abstrahlwinkel:	100°
Betriebstemperatur:	-30... +55 °C
Farbwiedergabe (Ra):	> 85
Lampenlebensdauer:	> 60.000 h
Material Gehäuse:	Aluminium
Material Abdeckung:	Sicherheitsglas, 4 mm
Höhe [B] x Breite [C]:	~28 mm x ~23 mm
Länge [A]:	205 mm
Gewicht:	200 g
Bruttogewicht:	300 g
Risikogruppe (DIN EN 62471):	freie Gruppe
Kennzeichnung:	CE, UKCA, ETL Listed (5003526)
Befestigungszubehör:	optional
Dimmbar:	optional über Zubehör
Gefertigt in:	Deutschland
Besonderheit:	sehr schlank und lichtstark, M8 Sensor-Steckverbindung, kaskadierbar

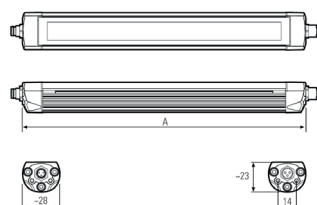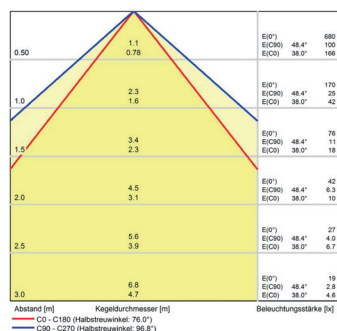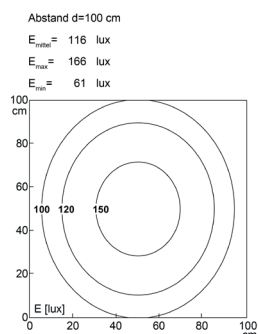

Elektrische Durchgangsverdrahtung (kaskadierbar) bis max. 4 A DC bei ta max. +40 °C
 Lampenlebensdauer in Betriebstunden (L80/B10)




LED Maschinenleuchte LED machine light



TUBELED_25, 205 mm (8,07''), cascable

Item number: 154010-02
EAN: 4260556625898

Order number:	154010-02
Model:	TUBELED_25
Type:	LED surface-mounted light for machines and systems
Illuminant:	SMD LED
Power consumption:	~4,3 W
Lamp luminous flux:	667 lm
Lamp luminous efficiency:	155 lm/W
Light distribution:	direct
Light colour:	daylight white (5200 - 5700K)
Connected load:	24V DC $\pm$ 10%
Connection (connector):	M8 A-type encoded
Degree of protection:	IP67
Class of protection:	III
Glare-free	diffused safety glass
Beam angle (optics):	100°
Operating temperature:	-30... +55 °C (-22... 131 °F)
Colour rendering (Ra):	> 85
Lamps lifetime:	> 60,000 h
Housing material:	aluminium
Cover material:	safety glass, 4 mm (0,16'')
Height [B] x Width [C]:	~28 mm x ~23 mm (~1,1" x ~0,91'')
Length [A]:	205 mm (8,07'')
Weight (net):	200 g (~7 oz)
Gross weight:	300 g (~11 oz)
Risk group (DIN EN 62471):	free group
Marking:	CE, UKCA, ETL Listed (5003526)
Mounting accessories:	optional
Dimmable:	optional via accessories
Made in:	Germany
Feature:	very slim and bright, M8 sensor connector, cascable

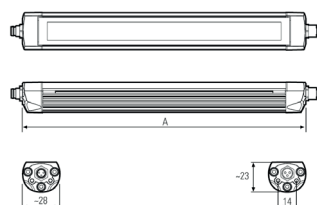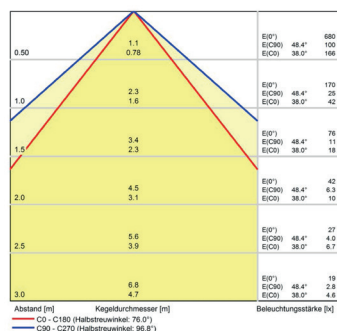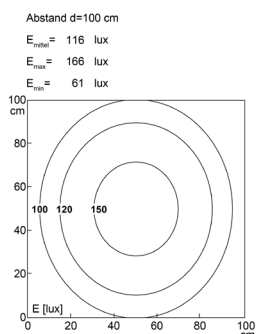

Several lights can be interlinked electrically. Electrical through-wiring (cascable) up to max. 4 A DC at ta max. +40 °C.
Lamps lifetime in operation hours (L80/B10)