

LED ELN 1120 PMMA_d-M8-57

Art. Nr. 1-000000-06131

Ktl. Nr. 15070250

EAN Nr. 4260654160468



Normen / Norms

DIN EN IEC 60598-1

DIN EN IEC 55015

DIN EN 61547

DIN EN 62471




Elektrische Rahmenbedingungen / Electrical characteristic

Netzanschluss / Main Supply	24 VDC
Leistung / Power	27 W
Dimmbar / Dimmable	extern PWM
Anschluss / Connection Type	Flansch, M8, 4-Pol, A-Codiert
Kaskadierbar / Cascadable	Nein
Polbild	


Licht / Light

Bestückt / Fitted With	LED
Lichtfarbe / Light Colour	5700 K
Lichtstrom / Luminous Flux	2950 lm
Effizienz / Efficiency	109 lm/W
Abstrahlwinkel / Beam Angle	120°
Farbtreue / Colour Rendering	RA / CRI >80
Photobiological Safety	RG-1

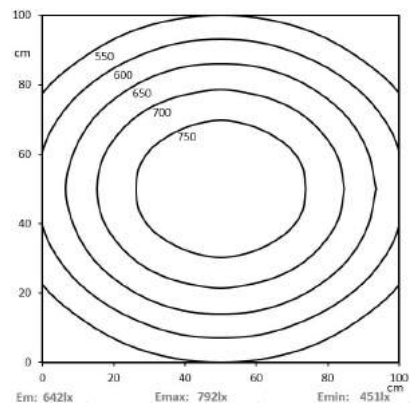

Mechanik / Mechanics

Gehäuse / Housing	Aluminium
Abdeckung / Cover	PMMA, Diffus
Befestigung / Fastening	Drehbar
Gewicht(Netto) / Weight(Net)	0,59 kg
Betriebstemperatur / Operating Temp.	-20°C / +45°C
Lebensdauer / Lifetime	min. 60000 h
Zubehör / Equipment	2x Endhalter

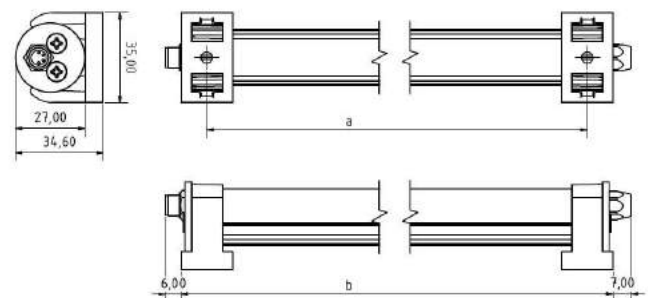

a= 1130mm b= 1146,5m

*Technische Änderungen vorbehalten | technical modifications reserved

rev.15.09.2023