


Product Information Sheet

COMMISSION DELEGATED REGULATION (EU) 2023/1669 with regard to the energy labelling of smartphones and slate tablets

1. Trademark		2. Model identifier	
Lenovo		Tab K11 (Enhanced Edition) (TB330FUP)	
3. General product parameters:			
Parameter		Value	
4. Device type		Tablet	
5. Operating system		Android	
6. Energy efficiency class		F	
7. Battery user-replaceable		No	
8. Battery endurance per cycle (END _{device} [h])		76	
9. Battery endurance in cycles - default settings [cycles]		1 000	
10. Rated battery capacity (C _{rated} [mAh])		6 820	
11. Shipped with protective cover		No	
12. Repeated free fall reliability test - falls without defect [n]		1	
13. Repeated free fall reliability test - falls without defect, tested in fully extended state [n]		n.a.	
14. Repeated free fall reliability class		E	
15. Ingress protection rating		IP52	
16. Specified immersion depth in water, in case of IPx8 [m]		n.a.	
17. Screen scratch resistance on Mohs hardness scale		5	
18. Charger	Required output power [W]	10	
	Receptacle type (at device end)	USB-C	
Repairability information:			
19. Minimum guaranteed availability of operating system security updates, corrective updates and functionality updates (years)		7	
20. Repairability Class (based on the index below)		A	
21. Repairability Index		4,03	
21a. Disassembly Depth (S _{DD}) score		2,90	
21b. Fasteners (type) score (S _F)		3,50	
21c. Tools (type) score (S _T)		3,55	
21d. Spare Part score (S _{SP})		5	
21e. Software Updates (duration) score (S _{SU})		5	
21f. Repair Information score (S _{RI})		5	
22. Weblink to information on spare parts availability for professional repairers and end users		https://pcsupport.lenovo.com/us/en/solutions/ht515951-tablet-product-self-repair-guidance	

23. Weblink to repair instructions for end-users	https://support.lenovo.com/us/en/solutions/HT517110
24. Weblink to indicative pre-tax prices	https://pcsupport.lenovo.com/us/en/solutions/ht515951-tablet-product-self-repair-guidance
Additional information:	
25. Minimum duration of the guarantee offered by the supplier [months]	24

Model placed on the Union market from 03/04/2024

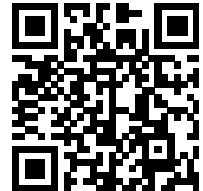

EPREL registration number: 2242258

<https://eprel.ec.europa.eu/qr/2242258>

Supplier: Lenovo (Slovakia) s.r.o. (Manufacturer)

Website: <https://www.lenovo.com>

Customer care service:

Name: Lenovo

Website: <https://www.lenovo.com>

Email: compliance@lenovo.com

Phone: +421 2 68688001

Address:

Landererova 12
811 09 Bratislava
Slovakia