


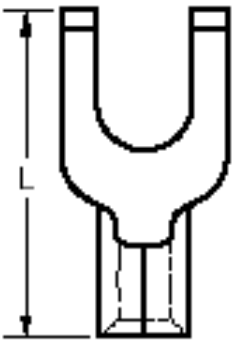

Part Number : [191180086](#)
Product Description : Krimptite Flanged Spade
Tongue Terminal for 12-10 AWG Wire, Stud
Size 8 (M4), Length 19.56mm
Series Number : 19118
Status : Active
Product Category : Ring and Spade Terminals
Engineering Number : C-117-08



Documents & Resources

Drawings
[191180086_sd.pdf](#)
[PK-19902-001-001.pdf](#)

3D Models and Design Files
[191180086_stp.zip](#)

Specifications
[PS-19902-011-001.pdf](#)
[PS-19902-013-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements
- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Ring and Spade Terminals
Series	19118
Description	Krimptite Flanged Spade Tongue Terminal for 12-10 AWG Wire, Stud Size 8 (M4), Length 19.56mm
Keyword	Spade Terminal, Spade Terminals
Product Name	Krimptite
Type	Spade
UPC	800755082814

Agency

CSA	LR18689
UL	E32244

Physical

Barrel Type	Closed
Insulation	None
Material - Plating Mating	Tin
Net Weight	1.511/g
Packaging Type	Bag
Plating min - Mating	4.064µm
Plating min - Termination	4.064µm
Stud Size	8 (M4)
Wire Size (AWG)	10, 12
Wire Size mm ²	4.00-6.00

Application Tooling

Global

Description	Part Number
PremiumGrade Hand Crimp Tool for Krimptite/Versakrimp Terminals and Splices, 22-10 AWG and 6.0mm ² - 0.5mm ²	<u>640030100</u>
Crimp Head for the AT-200 Pneumatic Hand Tool	<u>640070100</u>
ServiceGrade Hand Crimp Tool - Ratchet	<u>640160038</u>