


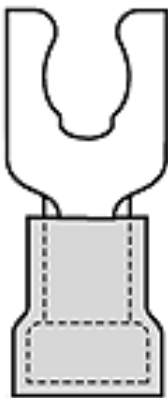

**Part Number :** [191150013](#)  
**Product Description :** Avikrimp Snap Spade  
Terminal for 22-18 AWG Wire  
**Series Number :** 19115  
**Status :** Active  
**Product Category :** Ring and Spade Terminals  
**Engineering Number :** AA-8714-08T



## Documents & Resources

**Drawings**  
[191150013\\_sd.pdf](#)

**3D Models and Design Files**  
[191150013\\_stp.zip](#)

**Specifications**  
[PS-19902-011-001.pdf](#)

## Product Environment Compliance

### Compliance

|                    |                                                                                       |
|--------------------|---------------------------------------------------------------------------------------|
| GADSL/IMDS         | Not Relevant                                                                          |
| China RoHS         |  |
| EU ELV             | Not Relevant                                                                          |
| Low-Halogen Status | Low-Halogen per IEC 61249-2-21                                                        |
| REACH SVHC         | Not Contained per D(2024)4144-DC (27 June 2024)                                       |
| EU RoHS            | Compliant per EU 2015/863                                                             |

### Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

### Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

## EU RoHS Certificate of Compliance

---

### Part Details

#### General

|              |                                                 |
|--------------|-------------------------------------------------|
| Status       | Active                                          |
| Category     | Ring and Spade Terminals                        |
| Series       | 19115                                           |
| Description  | Avikrimp Snap Spade Terminal for 22-18 AWG Wire |
| Keyword      | Spade Terminal, Spade Terminals                 |
| Product Name | Avikrimp                                        |
| Type         | Spade Snap                                      |
| UPC          | 800753091924                                    |

#### Agency

|     |         |
|-----|---------|
| CSA | LR18689 |
| UL  | E32244  |

#### Physical

|                           |                       |
|---------------------------|-----------------------|
| Barrel Type               | Closed                |
| Flammability              | 94V-2                 |
| Insulation                | Nylon (PA)            |
| Material - Plating Mating | Tin                   |
| Net Weight                | 0.834/g               |
| Packaging Type            | Adhesive Tape on Reel |
| Plating min - Mating      | 4.064µm               |
| Plating min - Termination | 4.064µm               |
| Stud Size                 | 8 (M4)                |
| Wire Insulation Diameter  | 3.60mm max.           |
| Wire Size (AWG)           | 18, 20, 22            |

---

# Application Tooling

## Global

| Description                                                           | Part Number      |
|-----------------------------------------------------------------------|------------------|
| ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press      | <u>192880023</u> |
| Mini-Mac Pneumatic Applicator for Ring and Spade Terminals, 22-18 AWG | <u>638851300</u> |