



LogiLink®

**4K Wireless BYOD
Presentation System, 16 to 1
50 m**

Art. No.: HDW0111
HDW0111AT



Seamless Connectivity, Unmatched Clarity!

Wirelessly transmits HDMI video and audio signals in UHD 4K over a distance of up to 50 m with an unobstructed view. Supports 16 sources to 1 output screen.

**4K
UHD**



Freedom from
Cables



 
Ultra High
Definition



Multi-Room
Use



Low
Latency



Wide
Compatibility




Plug &
Play



USB
Powered

Point-to-Multi-Point Connections: 16 TX to 1 RX

Quick and easy sharing from notebook or from a tablet/smartphone using AirPlay or Miracast to a HDMI TV/monitor.

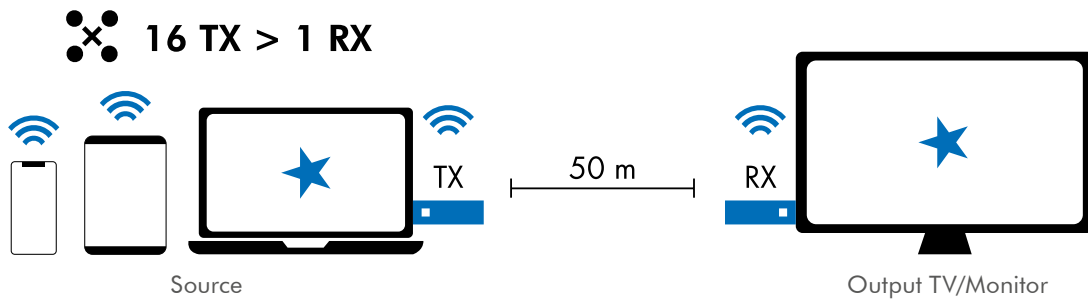

Enhanced Viewing Experience

Ultra-high-definition (4K) picture quality ensures crystal clear images and vibrant colors.

Freedom from Cables

Eliminates the need for HDMI cables, reducing clutter and providing a clean setup.

Low Latency

Ensures smooth, lag-free video and audio transmission, which is crucial for gaming and real-time presentations.

Ease of Setup

Plug-and-play functionality makes it easy to install and use without extensive configuration.

Multi-Room Use

Allows streaming from one source to multiple displays in different rooms, enhancing flexibility in device placement.

Portability

Compact design makes it easy to move and set up in different locations, suitable for both home and professional use.

Compatibility

Works with a wide range of devices, including TVs, projectors, laptops, and gaming consoles.

Wide Usage

Perfect for streaming movies, playing video games, watching sports; business meeting or educational presentations; events and presentations.



HDMI-A male



Reset button and LED indicator



Power supply through DC 5V USB-C port

Specifications:

Connection	TX/RX: 1x HDMI-A male, 1x USB-C female
HDMI Version	2.0/1.4
HDCP Version	2.2/1.4
Input Resolution (TX) Output Resolution (RX)	Up to 4K/30 Hz (TX) Up to 4K/60 Hz (RX)
Transmission Distance	Up to 50 m (unrestricted view)
Protocol	WPA2
Security	AES 128-bit encryption
Latency	100 ms (at 60 fps)
Wireless Standard	802.11ac
Frequency Range	TX: 5180–5240 MHz/5745–5825 MHz RX: 5180–5240 MHz/5745–5825 MHz
Max. Transmission Power	TX: 17.37 mW/18.23 mW RX: 22.02 mW/19.72 mW
Audio Format	PCM (2 channels)
Auto Pairing & Connection	Yes
LED Indication	Yes
Operating Temperature	0–40°C
Operating Humidity	10–80% RH (non-condensing)
Color	Black
Dimensions	TX/RX: 9.1 x 3.4 x 1.28 cm
Weight	TX: 28 g, RX: 25.5 g
Compatibility	Windows, macOS, iOS, iPadOS, Android
Power Supply	Powered through USB-C port (5 V/1 A, 5 W max.)

Art-No.	Package Contents	EAN Code
HDW0111	1x Transmitter, 1x Receiver, 2x HDMI Extension Cable, 2x USB-C to USB-A Cable, 1x User Manual	4052792075380
HDW0111AT (Additional TX Unit)	1x Transmitter, 1x HDMI Extension Cable, 1x USB-C to USB-A Cable, 1x User Manual	4052792075397

Package Information:

Art-No.	Packing Dimension	Packing Weight	Carton Dimension	Carton Q'ty	Carton Weight
HDW0111	119 x 119 x 48 mm	0.263 kg	530 x 270 x 270 mm	30 pcs	8.61 kg
HDW0111AT	76 x 119 x 48 mm	0.169 kg	370 x 230 x 310 mm	30 pcs	5.55 kg



*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.

Made in China