



LogiLink®

4K Wireless Video Extender Set


USB-C to HDMI, 4K, 30 m

Art. No.: HDW0104



Seamless Connectivity, Unmatched Clarity!

Wirelessly transmits HDMI video and audio signals in UHD 4K over a distance of up to 30 m with an unobstructed view.

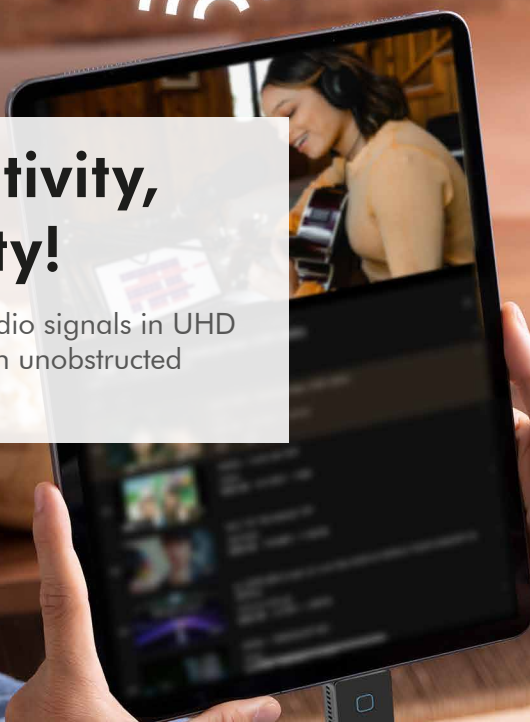

Freedom from
Cables



Ultra High
Definition



Low
Latency



Wide
Compatibility




Plug &
Play



USB
Powered

Point-to-Point Connection: USB-C to HDMI

Screen sharing from your notebook or tablet to a HDMI TV/Monitor.

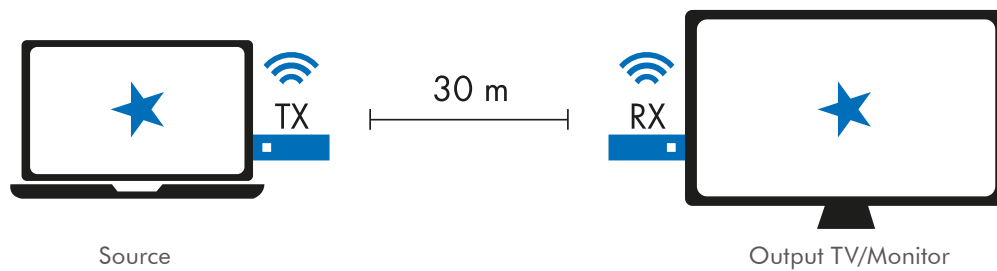

Enhanced Viewing Experience

Ultra-high-definition (4K) picture quality ensures crystal clear images and vibrant colors.

Freedom from Cables

Eliminates the need for HDMI cables, reducing clutter and providing a clean setup.

Low Latency

Ensures smooth, lag-free video and audio transmission, which is crucial for gaming and real-time presentations.

Ease of Setup

Plug-and-play functionality makes it easy to install and use without extensive configuration.

Portability


Compact design makes it easy to move and set up in different locations, suitable for both home and professional use.

Compatibility

Works with a wide range of devices, including TVs, projectors, laptops, and gaming consoles.

Wide Usage

Perfect for streaming movies, playing video games, watching sports; business meeting or educational presentations; events and presentations.

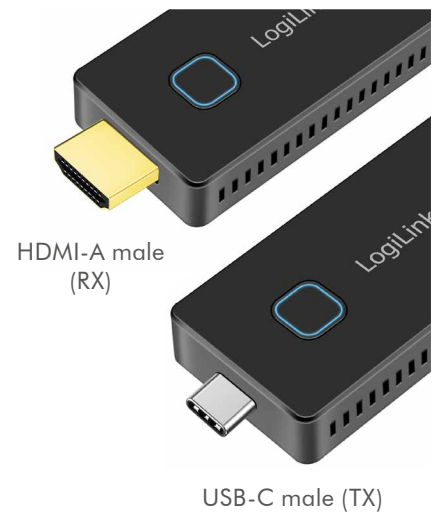

HDW0104



Made in China



*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.

Specifications:

Connection	TX: 1x USB-C male, 1x USB-C female RX: 1x HDMI-A male, 1x USB-C female
HDMI Version	2.0/1.4
HDCP Version	2.2/1.4
Input Resolution (TX) Output Resolution (RX)	Up to 4K/30 Hz (TX) Up to 4K/60 Hz (RX)
Transmission Distance	Up to 30 m (unrestricted view)
Protocol	WPA2
Security	AES 128-bit encryption
Latency	100 ms (at 60 fps)
Wireless Standard	802.11ac
Frequency Range	TX: 5180–5240 MHz/5745–5825 MHz RX: 5180–5240 MHz/5745–5825 MHz
Max. Transmission Power	TX: 17.37 mW/18.23 mW RX: 22.02 mW/19.72 mW
Audio Format	PCM (2 channels)
Auto Pairing & Connection	Yes
LED Indication	Yes
Operating Temperature	0–40°C
Operating Humidity	10–80% RH (non-condensing)
Color	Black
Dimensions	TX: 8.75 x 3.4 x 1.28 cm RX: 9.1 x 3.4 x 1.28 cm
Weight	TX: 37.5 g, RX: 25.5 g
Compatibility	Windows, macOS, iOS, iPadOS, Android
Power Supply	Powered through USB-C port (5 V/1 A, 5 W max.)

Package Contents:

- » 1x Transmitter
- » 1x Receiver
- » 1x HDMI Extension Cable
- » 1x USB-C Extension Cable
- » 2x USB-C to USB-A Cable
- » 1x User Manual

Package Information:

- » Packing Dimension: 119 x 119 x 48 mm
- » Packing Weight: 0.258 kg
- » Carton Dimension: 530 x 270 x 270 mm
- » Carton Q'ty: 40 pcs
- » Carton Weight: 10.97 kg



*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.



HDW0104



Made in China