


Produktdatenblatt

Product Data Sheet

2x USB Schutzkontakt-Steckdose 3,5A Anthrazit USB Typ A & C

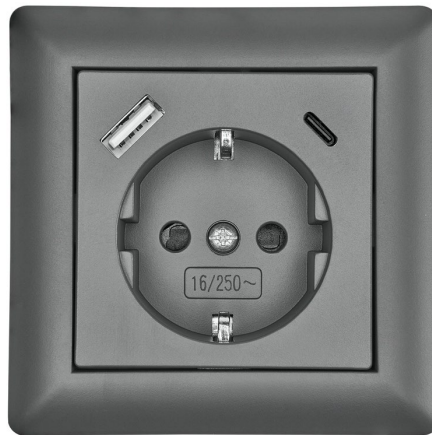

Basis Daten

Base Data

Artikelnummer <i>Articlenumber</i>	USB2203
Hersteller <i>Manufacturer</i>	LEDmaxx
Marke <i>Brand</i>	LEDmaxx
Gehäusematerial <i>Housing material</i>	Kunststoff / Metall <i>plastic / metal</i>
Farbe <i>Colour</i>	Anthrazit RAL7016 <i>anthracite RAL7016</i>

Elektrische Daten

Electrical Data

Betriebsspannung in V <i>Operating voltage in V</i>	max. 250,0V/AC · 50/60Hz
Netzsteckdose Output <i>Mains socket output</i>	max. 3680,0W (230,0V AC · 50/60Hz · 16,0A)
USB Output <i>USB Output</i>	5,0V DC · max. 3,5A · 17,5W
Durchschnittliche Effizienz in % <i>Average efficiency in %</i>	82,9
Effizienz bei geringer Last in % <i>Efficiency at low loads in %</i>	78,1
Leistungsaufnahme bei Nulllast in W <i>Efficiency at null loads in %</i>	0,10
Betriebstemperatur in °C <i>Working temperature in °C</i>	-10 ... +40

Abmessungen und Gewicht

Dimension and Weight

Breite in mm <i>Width in mm</i>	80
Höhe in mm <i>Height in mm</i>	80
Tiefe in mm <i>Depth in mm</i>	44
Einbautiefe in mm <i>Installation Depth in mm</i>	ca. 32
Rahmenmaß in mm <i>Frame size in mm</i>	80 x 80
Nettogewicht in g <i>Net. Weight in g</i>	135

Bestellungen und Verpackungsinformation

Ordering and Packaging Information

Artikelnummer <i>Article number</i>	EAN <i>Barcode</i>	Stück <i>Pieces</i>	Abmessungen <i>Dimension (in mm)</i>	Gewicht <i>Weight gross (in g)</i>	Volumen <i>Volume (in dm³)</i>
USB2203	4251351806025	1	85 x 85 x 54	145	0,39
USB2203	4251351806025	100	435 x 240 x 355	1450	37,06