


Description : Hearing Aid Battery
Chemical system : Zinc / Air
Nominal voltage : 1.45Volts
IEC Standard Test capacity : 189mAh
IEC Wireless Test capacity : 173mAh
Dimensions : Ø7.8mm x 3.5mm
Average weight : 0.58 grams
Volume : 0.16 ccm
Operation temperature: 0°C - 45°C
Storage temperature : 10°C ~30°C
Short Exposition : -10°C ~65°C
Shelf life : 4 years at room temperature

Model no.: **ZA312F**

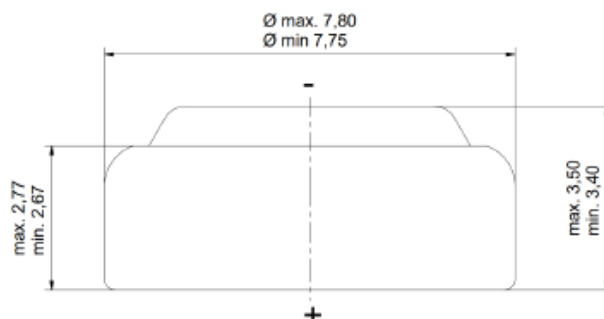


Cross References:

IEC	JIS	Panasonic	Varta
PR 41	PR312	PR312	P312

Discharge Characteristics

Typical discharge characteristics at 20°C / 55% r.h.:

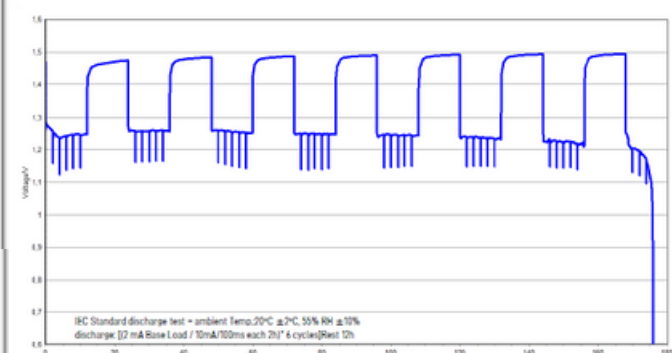

The information (subject to change without prior notice) contained in this document is for reference only and should not be used as a basis for product guarantee or warranty. For applications other than those described here, please consult your nearest GP Sales and Marketing Office or Distributors.