

PATH TO THE FUTURE


Der PRO DP180 AI ist ein Desktop-PC, der von Intel Core Ultra-Prozessoren betrieben wird und USB 10Gbps Type-C und Type-A sowie Dual-LAN unterstützt, was ihn ideal für den Einsatz zu Hause und im Büro macht.



Picture and logos

SELLING POINTS

- Windows 11 Home - MSI empfiehlt Windows 11 Pro für Unternehmen
- Bis zu Intel® Core™ Ultra 7 Prozessor
- Erhältlich mit bis zu NVIDIA GeForce RTX™ 5070-Grafikkarte
- Microsoft Copilot verbessert Ihre Produktivität workplace productivity
- Dual-channel DDR5 U-DIMMs Arbeitsspeicher
- Thunderbolt™ 4 Unterstützung: Bis zu 40Gbps für schnellsten Datentransfer
- Wi-Fi 7 for efficient AI workload management
- Dual LAN Design (2.5G LAN)
- Gehäuse-Einbruchserkennung verbessert die physische Sicherheit und den Schutz der IT-Infrastruktur
- Inspiriert von Militärstandards auf dauerhafte Robustheit und Leistung getestet
- Hergestellt aus PCR-recyceltem Kunststoff; FSC™-zertifizierter Karton; Weniger Abfall dank recycelter Formmasse (100 % recycelbar); In der Fabrik zu 99 % mit erneuerbarer Energie produziert

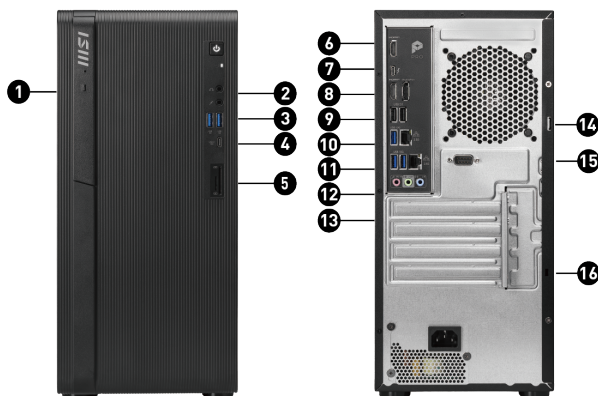

1. 1x ODD (Optional)
2. 1 x Kopfhörerausgang ; 1 x Mikrofoneingang
3. 2x USB 5Gbps Typ-A
4. 1x USB 10Gbps Typ-C
5. 1x Kartenleser (Unterstützt SD & Micro SD Card)
6. 1x HDMI Ausgang
7. 1x Thunderbolt 4
8. 1x HDMI Ausgang; DisplayPort (1.4)
9. 2x USB 2.0 Typ-A
10. 1x USB 10Gbps Typ A ; 1x RJ45 LAN (2.5G)
11. 2x USB 10Gbps Typ A ; 1x RJ45 LAN (2.5G)
12. 3x Audioanschlüsse
13. 1x Grafikkarte (*Grafikkarte je nach Konfiguration)
14. 1x Padlock
15. 1x COM Anschluss
16. 1x Kensington Lock



PRO DP180 AI

PRO DP180 AI 8HG-1436AT

SPECIFICATION

Betriebssystem	Betriebssystem	Windows 11 Pro
Prozessor	CPU Number	Intel Core Ultra 5 processor 225
	CPU Clock	3.3GHz
	CPU Cores	10
	TDP	65W
	Cache	20 MB Intel® Smart Cache
	Threads	10
	Max Turbo Frequency	up to 4.90 GHz
	CPU Cooler	Air cooling
	Platform TOPS	up to 36 TOPs
	NPU TOPS	up to 13 TOPs
Chipsatz	Chipsets	H810
Grafik	GPU1 VRAM Size	N/A
	VGA I/O Port	N/A
	GPU1 Vendor	N/A
	GPU1 MKT Name	N/A
Arbeitsspeicher	Memory Size	16GB(16GB*1)
	Memory Type	DDR5 SDRAM
	Module Type	U-DIMM
	Memory Slot (Total/Free)	2/1
	Max Capacity	Max 64GB
Speicher	SSD Interface	PCIe GEN4x4 NVMe
	SSD Form Factor	M.2 2280 M-KEY
	SSD Config	512GB*1
	SSD Size	512GB
	HDD1 Interface	N/A
	HDD1 Form Factor	N/A
	HDD1 Size	N/A
	HDD1 RPM	N/A
	ODD(Type)	N/A
	ODD Height	N/A
	ODD Type	N/A
	M.2 slots (Total/Free)	1/0
	2.5" Drive Bays (Total/Free)	1/1
	3.5" Drive Bays (Total/Free)	1/1
Audio	Audio Chipset	Realtek ALC897
	Audio Type	7.1 Channel HD Audio
Kommunikation	LAN	2x Intel I226-V
	WLAN Version	Wi-Fi 6E+BT
	BT Version	5.3
	WLAN	INTEL/AX211.NG.WG.NV
Schnittstellen (Vorne)	Audio Mic-in	1
	Audio Headphone-out	1
	USB 3.2 Gen 2 (10G) Type C	1
	USB 3.2 Gen 1 (5G) Type A	2
	Card Reader	1
Schnittstellen (Rückseite)	USB 2.0 Type A (R)	2
	RJ45	2
	HDMI out	2x (HDMI v2.1 Support up to 4K@60Hz)
	DP out	1x (v1.4)
	PS/2	1
	COM Port	1
	USB 3.2 Gen 1 (5G) Type A (R)	2
	Lock type	Kensington Lock, Padlock Lock
Power	Power	500W
	Power Certification	80PLUS GOLD
	Formfactor	TFX
	Type	POWER SUPPLY

Abmessungen & Gewicht	Product Dimension (WxDxH) (mm)	168 x 355.05 x 369.40
	Product Dimension (WxDxH) (inch)	6.61 x 13.98 x 14.54
	Inside Carton Dimension (WxDxH) (mm)	N/A
	Inside Carton Dimension (WxDxH) (inch)	N/A
	Outer Carton Dimension Standard (WxDxH) (mm)	455 x 240 x 485
	Outer Carton Dimension Standard (WxDxH) (inch)	17.91 x 9.45 x 19.09
	Weight (Net kg)	5.69
	Net Weight (lbs)	12.54
	Weight (Gross kg)	7.89
	Gross Weight (lbs)	17.39
	Liter	18
	Pint	38.04
Lagerung & Zertifikationen	Operating, Storage Temperature	0° C ~ 35° C ; -20° C ~ 60° C
	Operating, Storage Humidity	0% ~ 85%;0% ~ 90%
	Regulatory Compliance	BSMI, CB/CE, CEC, ERP lot 3, Energy Star, Epeat Sliver, RH, UL(CUL)
Garantie	Warranty	24months
Zubehör	Keyboard Interface	N/A
	Mouse Interface	N/A
	Power Cord	1
	AC Adaptor	N/A
	Warranty Card	N/A
	Quick Guide	3
	User Manual	N/A
	VESA Mount kit	N/A
	Keyboard	N/A
	Mouse	N/A
	Power Switch	N/A
Barcode Info	EAN	4711377440158
Model	Part No	9S6-B0A781-1436
	MKT Name	PRO DP180 AI 8HG
	MKT Spec	PRO DP180 AI 8HG-1436AT
	Color	ID1/Black-Black-Black
	SKU Number	00B0A781-1436
	Model	B0A7
	Entity MKT Name	PRO DP180 AI 8HG-1436AT
Security	TPM module	dTPM
	Chassis Lock	Kensington Lock, Padlock
	Chassis Intrusion	Support