

Be Your Window To The World


Der MSI Cubi N ADL ist ein energiesparender Desktop-PC im Handformat. Er eignet sich für jegliche Multimediaanwendungen als auch für den klassischen Office Bereich. Im Gegensatz zu einem großen Desktop-PC benötigt der Cubi N keinen großen Stauraum und kann mittels VESA-Halterung direkt an einem Monitor oder unter dem Tisch befestigt werden. Mittels USB 3.2 bietet der Cubi N eine vielfältige Schnittstelle für die aktuellsten Endgeräte. Durch die ausgezeichnete Wärmeregulierung ist das Gerät auch im vollen Betrieb kaum hörbar und sorgt für eine angenehme Arbeitsumgebung.



Picture and logos

SELLING POINTS

- Windows 11 Home – MSI empfiehlt Windows 11 Pro für Unternehmen
- Mit Intel Alder Lake Prozessoren
- Lüfterloses Design: Geräuscharm, energieeffizient und staubdicht, was zu geringeren Ausfallzeiten und einer längeren Lebensdauer führt (optional in Modellvariante Cubi N ADL S)
- Unterstützt 4K-UHD-Displays
- Unterstützt bis zu drei Displays, sodass du mehr sehen und mehr tun kannst
- Duale Netzwerklösung für Internet und Intranet
- Erhalte die gesamte Leistung von USB 3.2 Gen 2
- dTPM 2.0-Design sichert deine vertraulichen Daten mit Verschlüsselung
- 24/7-Zuverlässigkeitstest
- Unterstützt standardmäßige VESA-Halterung und externen Netzschalter (optional)
- Unterstützt MSI Cloud Center und MSI Center-App

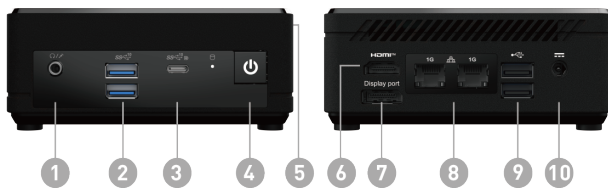

1. 1x Mic-in/ Headphone-out combo
2. 2x USB 3.2 Gen 2 Type A
3. 1x USB 3.2 Gen 2 Type C (DP Alternate)
4. 1x Power Button
5. 1x Kensington Lock
6. 1x HDMI™ (2.1)
7. 1x DP-out (1.4)
8. 2x RJ45 (LAN)
9. 2x USB 2.0 Type A
10. DC Jack

SPECIFICATION

Betriebssystem	Betriebssystem	N/A
	Operating Systems	N/A
Prozessor	CPU Number	Intel Processor N100
	CPU Clock	0.8GHz
	CPU Cores	4
	TDP	6W
	Cache	6 MB
	Threads	4
	Max Turbo Frequency	up to 3.40 GHz
	CPU Cooler	Air cooling
	Platform TOPS	N/A
	NPU TOPS	N/A
Model	MKT Name	Cubi N ADL
	MKT Spec	Cubi N ADL-290XDE
	Color	ID1/Black-Black-Black
	SKU Number	00B0A911-290
	Part No	9S6-B0A911-290
	Model	B0A9
Chipsatz	Chipsets	Soc
Arbeitsspeicher	Memory Size	8GB(8GB*1)
	Memory Type	DDR4 SDRAM
	Memory Speed	1600(3200)MHz
	Module Type	SO-DIMM
	Memory Slot(Total)	1
	Memory Slot(Free)	0
	Max Capacity	Max 16GB
	Memory Slot (Total/Free)	1/0
Grafik	GPU1 VRAM Size	N/A
	VGA I/O Port	N/A
	GPU1 Vendor	N/A
	GPU1 MKT Name	N/A
	GPU1 Number	N/A
Speicher	SSD Interface	PCIe GEN3x4
	SSD Form Factor	M.2-2280 M-KEY
	SSD Config	128GB*1
	SSD Size	128GB
	HDD1 Interface	N/A
	HDD1 Form Factor	N/A
	HDD1 Size	N/A
	HDD1 RPM	N/A
	ODD(Type)	N/A
	ODD Height	N/A
	ODD Type	N/A
	M.2 slots (Total/Free)	1/0
	2.5" Drive Bays (Total/Free)	1/1
	3.5" Drive Bays (Total/Free)	0/
	M.2 slots(Total)	1
	M.2 slots(Free)	0
	2.5" Drive Bays(Total)	1
	2.5" Drive Bays (Free)	1
	3.5" Drive Bays(Free)	0
Audio	Audio Chipset	Realtek ALC256
	Audio Type	2.1 Channel HD Audio
	D-MIC	N/A
Kommunikation	LAN	2x Realtek RTL8111H
	WLAN Version	Wi-Fi 5+BT
	BT Version	5
	WLAN	AzureWave/AW-CB515NF

Schnittstellen (Vorne)	Mic-in/Headphone-out combo	1
	USB 3.2 Gen 2 (10G) Type C	1x USB 3.2 Gen 2 Type C (DisplayPort Alternate)
	USB 3.2 Gen 2 (10G) Type A	2
	USB 4 (40G) Type C	N/A
	Copilot Button	N/A
Schnittstellen (Rückseite)	USB 2.0 Type A (R)	2
	RJ45	2
	HDMI out	1x (v2.1)
	DP out	1x (v1.4)
	Lock type	Kensington Lock
	USB 4 (40G) Type C (R)	N/A
	Configurable port	N/A
Schnittstellen (Seite)	Mic-in/Headphone-out combo	1
	USB 3.2 Gen 2 (10G) Type C	1x USB 3.2 Gen 2 Type C (DisplayPort Alternate)
	USB 3.2 Gen 2 (10G) Type A	2
Power	Power	65W
	Power Certification	N/A
	Formfactor	N/A
	Type	ADAPTOR
VESA	VESA size	100 x 100 mm
Garantie	Warranty	24months
Abmessungen & Gewicht	Product Dimension (WxDxH) (mm)	124 x 124 x 53.7
	Product Dimension (WxDxH) (inch)	4.88 x 4.88 x 2.11
	Inside Carton Dimension (WxDxH) (mm)	205 x 220 x 94
	Inside Carton Dimension (WxDxH) (inch)	8.07 x 8.66 x 3.7
	Outer Carton Dimension Standard (WxDxH) (mm)	221 x 506 x 469
	Outer Carton Dimension Standard (WxDxH) (inch)	8.7 x 19.92 x 18.46
	Weight (Net kg)	0.54
	Net Weight (lbs)	1.19
	Weight (Gross kg)	1.39
	Gross Weight (lbs)	3.06
	Liter	0.7L
	Pint	0.7L
Lagerung & Zertifikationen	Regulatory Compliance	BSMI, CB/CE, CEC, ERP lot 3, Energy Star, FCC(Class B), RCM(C-Tick), RH, UL(CUL), VCCI
	Operating, Storage Temperature	0° C ~ 35° C ; -20° C ~ 60° C
	Operating, Storage Humidity	0% ~ 85%;0% ~ 90%
Zubehör	AC Adaptor	1
	Power Cord	1
	Warranty Card	N/A
	Quick Guide	3
	User Manual	N/A
	VESA Mount kit	1
	Keyboard	N/A
	Keyboard Interface	N/A
	Mouse	N/A
	Mouse Interface	N/A
	Power Switch	N/A
Barcode Info	EAN	4711377434645
Security	TPM module	dTPM
	Chassis Lock	Kensington Lock