


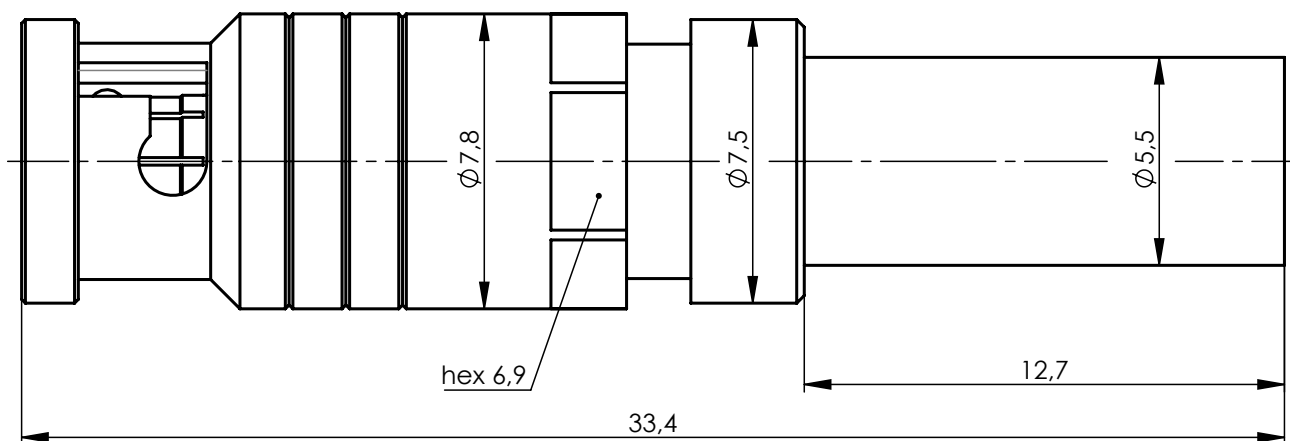

Mechanical characteristics

cable group
interface dimensions acc. to assembly code
center conductor
outer conductor
mating life

Components

center contact
outer contact
crimp ferrule
other metal parts
insulator

Electrical characteristics

impedance
frequency
return loss
working voltage
voltage proof
insulation resistance
contact resistance
center contact
outer contact

Environmental

operating temp.
RoHS compliant

Mechanische Eigenschaften

Kabelgruppe

Steckgesicht nach Montageanleitung
Innenleiter
Außenleiter
Steckzyklen

Bauteile

Innenkontakt
Außenkontakt
Crimprohr
sonstige Metallteile
Isolierung

Elektrische Eigenschaften

Wellenwiderstand
Frequenz
Rückflusdämpfung
Betriebsspannung
Prüfspannung
Isolationswiderstand
Durchgangswiderstand
Innenkontakt
Außenkontakt

Umgebung

Betriebstemperatur
RoHS konform

G41: 0.6/2.8 AF Draka, 0.6/2.8C-HM (FR-NC) Bedea, 1855ABelden HDTV Miniature Precision Video Cable, 46899 Belden, Image 360 Argosy, 1855NH Belden Digital Video Coax, FRNC 0.6/2.8 AF (Minik.) PKI, SDV Canford, VDM230 Gepco, VK5/0.6 FRLS 0.6/2.8 Percon without standard / ohne Norm
A4742
crimp
crimp
≥ 500

Materials / Material

BeCu
brass / Messing
brass / Messing
brass / Messing
PTFE

Finish / Oberfläche


Cu1Ni2Au0,2
Cu2Ni5
Cu2Ni5
Cu2Ni5

75 Ω
0-4,5 GHz
TBD
≤ 170 V_{eff} / 50 Hz
500 V_{eff} / 50 Hz
≥ 10 GΩ

 
≤ 5.0 mΩ
≤ 2.5 mΩ

-55°C / +155°C
2011/65/EU

M 1:1

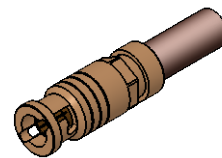

Änd./ rev. index	Änderungs-Nr. / revision code	Datum/ date	Name/ name		Datum/ date	Name/ name	Gewicht/ weight [g]
				gez./ drawn	20.01.2020	MA	
				gepr./ appr.	21.01.2020	BJ	ca./approx.
				Maßstab/ scale 5:1 (1:1)	Benennung/ title Mini HD BNC Straight Plug Mini HD-BNC-Kabelstecker		
				untol. Maße/ dim. without tolerances according to	Unterl./ doc. type K	Zeichnungsnr./ drawing no. J01290C0064	
				Ersatz für/ replaces			

	Telegärtner
	Maße/ dimensions: mm
Original : DIN A4	
Blatt/ sheet 1 von/ of 1	