

PATH TO THE FUTURE


Der MSI Infinite Z3 Gaming-Desktop ist maßgeschneidert für Gamer, deren unstillbarer Drang zum Spielen niemals nachlässt. Ausgestattet mit der weltweit besten Gaming-Hardware, die mit KI integriert ist, und zahlreichen Anpassungswerkzeugen ist dieser Desktop dein zuverlässiger Begleiter für endlose Stunden voller Gaming-Spaß. Fordere deine eigenen Grenzen heraus!



Picture and logos

SELLING POINTS

- Windows 11 Home/Windows 11 Pro (MSI empfiehlt Windows 11 Pro für Unternehmen.)
- Bis zu AMD® Ryzen™ 9000X3D Prozessor
- Bis zu MSI GeForce RTX™ 5090 Grafikkarten (AI-Beschleuniger)
- AI-Gaming-Desktop – KI-gesteuerte Verbesserungen bei Kühlung, Gaming und Game-Streaming
- MSI X3D Gaming Mode – Steigert die Gaming-Leistung um 2 % bis 20 %
- Silent Storm Cooling AI – Optimiert den airflow, indem die Lüftergeschwindigkeit mit AI-Algorithmen angepasst wird.
- 360-mm-AIO-Wasserkühlung – Leitet die Wärme von High-End-CPUs effizient ab.
- Glacier Armor – Mit umfangreichen Kühlkörpern an VRM, SSD, PCH und Speicher für ein optimiertes Wärmemanagement.
- Unterstützt PCIe 4.0 SSD – Lade deine Spiele in Sekundenschnelle
- 8-poliger Stromanschluss – Ein zusätzlicher integrierter PCIe-Stromanschluss sorgt für eine konstante GPU-Leistung bei KI-Computing-Aufgaben
- Einfach aufzurüsten – So kannst du deine Teile ganz leicht upgraden
- Mystic Light RGB LED-Design, um deinen Gaming-PC individuell zu gestalten
- Transparente Seitenwand erfüllt EMI-Standard
- 5G-LAN- und WiFi 6E-Technik – Gaming-Erlebnis ohne Verzögerungen

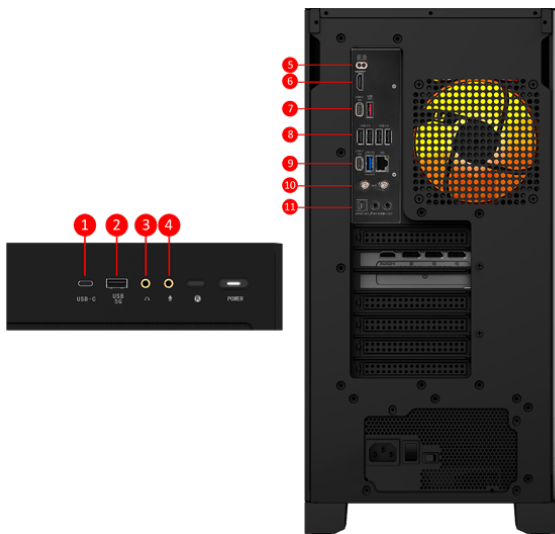

1. 1x USB 5Gbps Type C
2. 1x USB 5Gbps Type A
3. 1 x Headphone out
4. 1x Mic in
5. Flash Bios Button / Clear CMOS Button
6. 1x HDMI out
7. 1x USB 10Gbps Type C / 1x USB 10Gbps Type A
8. 4x USB 2.0 Type A
9. 1x USB 10Gbps Type C / 1x USB 5Gbps Type A / 1x RJ45 (5G LAN)
10. 2x Wi-Fi Antenna
11. 1x S/PDIF / 2x Audio Jacks



SPECIFICATION

Betriebssystem	Betriebssystem	Windows 11 Home
Prozessor	CPU Number	AMD Ryzen 7 9800X3D
	CPU Clock	4.7GHz
	CPU Cores	8
	TDP	120W
	Cache	8 MB
	Threads	16
	Max Turbo Frequency	up to 5.2 GHz
	CPU Cooler	Liquid cooling
	Platform TOPS	N/A
	NPU TOPS	N/A
Chipsatz	Chipsets	B850
Grafik	GPU1 VRAM Size	16G
	VGA I/O Port	HDMIx1, Display Portx3
	GPU1 Vendor	NVIDIA
	GPU1 MKT Name	GeForce RTX 5070 Ti
Arbeitsspeicher	Memory Size	32GB(16GB*2)
	Memory Type	DDR5 SDRAM
	Module Type	U-DIMM
	Memory Slot (Total/Free)	4/2
	Max Capacity	Max 128GB
Speicher	SSD Interface	PCIe GEN4x4
	SSD Form Factor	M.2-2280 M-KEY
	SSD Config	1TB*1
	SSD Size	1TB
	HDD1 Interface	N/A
	HDD1 Form Factor	N/A
	HDD1 Size	N/A
	HDD1 RPM	N/A
	ODD(Type)	N/A
	ODD Height	N/A
	ODD Type	N/A
	M.2 slots (Total/Free)	3/2
	2.5" Drive Bays (Total/Free)	1/1
	3.5" Drive Bays (Total/Free)	2/2
Audio	Audio Chipset	Realtek ALC897
	Audio Type	7.1 Channel HD Audio
	D-MIC	N/A
Kommunikation	LAN	Realtek RTL 8126-VB-CG
	WLAN Version	Wi-Fi 6E+BT
	BT Version	5.3
	WLAN	AMD/RZ616
Schnittstellen (Vorne)	Audio Mic-in	1
	Audio Headphone-out	1
	USB 3.2 Gen 1 (5G) Type C	1
	USB 3.2 Gen 1 (5G) Type A	1
	USB 4 (40G) Type C	N/A
	Copilot Button	N/A
Schnittstellen (Rückseite)	USB 2.0 Type A (R)	4
	RJ45	1
	WiFi Antenna	2
	HDMI out	1x (v2.1), NA
	Audio jack	2x (Line out / MIC in)
	S/PDIF	1
	Flash BIOS Button	1
	USB 3.2 Gen 2 (10G) Type C (R)	2
	USB 3.2 Gen 2 (10G) Type A (R)	1
	USB 3.2 Gen 1 (5G) Type A (R)	1

Power	Power	850W
	Power Certification	80PLUS GOLD
	Formfactor	ATX
	Type	POWER SUPPLY
Abmessungen & Gewicht	Product Dimension (WxDxH) (mm)	235.1 x 481.23 x 485
	Product Dimension (WxDxH) (inch)	9.26 x 18.95 x 19.09
	Inside Carton Dimension (WxDxH) (mm)	N/A
	Inside Carton Dimension (WxDxH) (inch)	N/A
	Outer Carton Dimension Standard (WxDxH) (mm)	590 x 327 x 611
	Outer Carton Dimension Standard (WxDxH) (inch)	23.23 x 12.87 x 24.06
	Weight (Net kg)	14.91
	Net Weight (lbs)	32.87
	Weight (Gross kg)	17.18
	Gross Weight (lbs)	37.88
	Liter	40
	Pint	84.53
Lagerung & Zertifikationen	Operating, Storage Temperature	0° C ~ 35° C ; -20° C ~ 60° C
	Operating, Storage Humidity	0% ~ 85%;0% ~ 90%
	Regulatory Compliance	BSMI, CB/CE, ERP lot 3, FCC(Class B), RCM(C-Tick), RH, UL(CUL), VCCI
Garantie	Warranty	36months
Zubehör	Keyboard Interface	N/A
	Mouse Interface	N/A
	Power Cord	1
	AC Adaptor	N/A
	Warranty Card	N/A
	Quick Guide	4
	User Manual	N/A
	VESA Mount kit	N/A
	Keyboard	N/A
	Mouse	N/A
	Power Switch	N/A
Barcode Info	EAN	4711377432214
Model	Part No	956-B94221-882
	MKT Name	MPG Infinite Z3 X3D
	MKT Spec	MPG Infinite Z3 X3D-882AT
	Color	ID1/Black-Black-Black
	Model	B942
Security	TPM module	N/A
	Chassis Lock	N/A
	Chassis Intrusion	N/A