

FlexBeam

ADJUSTABLE BEAM RECHARGEABLE FLASHLIGHT

1200 LUMENS


Discover the best of both worlds with the FlexBeam flashlight - a perfect blend of flood and spot light capabilities. Boasting 1200 max lumens and a 700-meter throw, its head can rotate for infinite adjustments between flood and throw modes. This light is also perfect for hunting applications. We have designed and rigorously tested this light to withstand recoil for the highest of caliber applications. Zoomable-focus flashlights are still a bit of a novelty feature, but Powertac is changing the game with the FlexBeam. This best-in-class light has a twistable head to control the beam output, ranging from a tight long-range beam to a wide luminous flood. Pair this with the tactical one-button tailswitch, and you have 100% brightness control with just one hand. Most other adjustable beam lights on the market simply slide forward and back with nothing to keep the light set to the desired beam. Our unique helical design allows the head to be rotated to the desired position and will hold that position, even with any harsh sudden movement, such as a recoil situation. Whether for EDC or hunting applications, the FlexBeam has you covered.

Battery: (1) 18650 Rechargeable Li-ion or (2) CR123A
NOT compatible with RC123A/16340

Size: Length: 140.8mm
Bezel Diameter: 36.5mm
Body Diameter: 23mm

Weight: 105g (without battery)

18650 Mode:	Firefly	Low	Medium	High	Turbo	Strobe
(2600 mAh) Max Output:	0.1lm	62lm	220lm	580lm	1200lm	1200lm
Runtime:	25 Days	23 hrs	6.2 hrs	3.68hrs	3.4 hrs	6.3 hrs
2 x CR123A Max Output:	0.1lm	62lm	220lm	—	—	220lm
(3V) Runtime:	20.6 Days	11.5hrs	2.6hrs	—	—	4.8 hrs

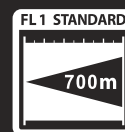

ALL PERFORMANCE DATA ARE RESULTS OF TESTING TO ANSI / NEMA FL1-2019 STANDARDS



Zoom IN/OUT

KIT INCLUDES:

- FLEXBEAM FLASHLIGHT
- USB MAGNETIC CABLE
- 18650 RECHARGEABLE BATTERY
- NYLON HOLSTER
- SPARE O-RINGS
- LANYARD
- INSTRUCTION MANUAL

MODEL#FLEXB

BEST FOR SPOTLIGHT OR FLOOD

- ▶ Infinitely Adjustable Beam Option
- ▶ Powerful Spot and Wide-Angle Flood
- ▶ 700 Meter Throw in Beam Only Mode
- ▶ Rugged Internals-Built to Handle Recoils



POWERTAC.COM