




PURI

spot for 240V 3-phase track, QPAR51, matt black, max. 50W, incl. 3-phase adapter

Adjustable high-voltage spot PURI with suitable adapter for the 240V 3-phase track system. The luminaire is made of aluminium and, thanks to the GU10 socket, is suitable for both halogen and LED lamps. A deco ring is included to place on the lamp for halogen lamps with 5 cm diameter.

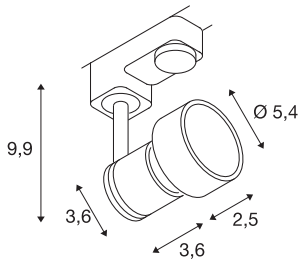

TECHNICAL DATA

Item no.:	153560
Socket	GU10
Lamp	QPAR51
Number of sockets	1
Lamps included	Yes
Primary nominal voltage	220-240V ~50/60Hz mA/V
Tilt range	85 °
Horizontal rotation range	350 °
Length	8.4 cm
Height	9.9 cm
Diameter	3.6 cm
Net weight	0.177 kg
Gross weight	0.229 kg
IP Code	IP 20
Safety class	II
Assembly	Surface
Assembly details	Ceiling,Track Ceiling,Track Wall,Wall
Wattage	50 W
Color	black
BIG WHITE Page	484

Recommended lamp

1004972	LED QPAR51 , lightbulb GU10 2700K 36°
1004973	LED QPAR51 , lightbulb GU10 300K 36°
1004974	LED QPAR51 , lightbulb GU10 4000K 36°
1005081	LED lightbulb QPAR51 , GU10, 4000- K, grey