


# Intellinet Network Patch Cable, Cat6A, 10m, Red, Copper, S/FTP, LSOH / LSZH, PVC, RJ45, Gold Plated Contacts, Snagless, Booted, Polybag - Patch-Kabel - RJ-45 (M)

bis RJ-45 (M) - 10 m - SFTP - PiMF - CAT 6a - IEEE 802.3af - halogenfrei - geformt - verseilt - Rot

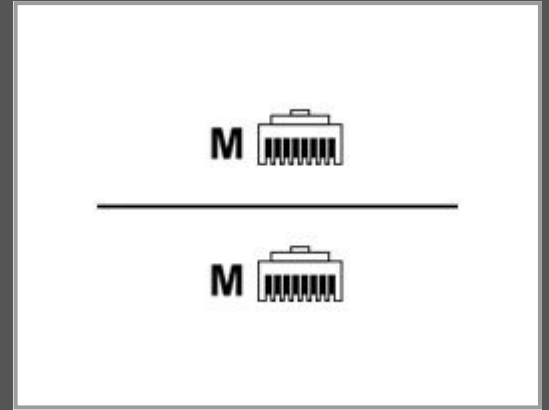

Gruppe	Kabel / Adapter
Hersteller	Intellinet
Hersteller Art. Nr.	736879
EAN/UPC	0766623736879

## Beschreibung

Intellinet Network Patch Cable, Cat6A, 10m, Red, Copper, S/FTP, LSOH / LSZH, PVC, RJ45, Gold Plated Contacts, Snagless, Booted, Polybag - Patch-Kabel - RJ-45 (M) bis RJ-45 (M) - 10 m - SFTP, PiMF - CAT 6a - IEEE 802.3af - halogenfrei, geformt, verseilt - Rot

## Hauptmerkmale

Produktbeschreibung	Intellinet Network Patch Cable, Cat6A, 10m, Red, Copper, S/FTP, LSOH / LSZH, PVC, RJ45, Gold Plated Contacts, Snagless, Booted, Polybag - Patch-Kabel - 10 m - Rot
Typ	Patch-Kabel - CAT 6a - IEEE 802.3af
Technologie	SFTP, PiMF
Abschirmungsmaterial	Aluminium-Myar-Folie mit verzinnem Kupfergeflecht
Drähte pro Kabel	8 Drähte
Leistungsmerkmale	Halogenfrei, geformt, verseilt, GHMT-zertifiziert
Länge	10 m
Anschluss	RJ-45 - männlich
Stecker (zweites Ende)	RJ-45 - männlich
Farbe	Rot

Technische Daten © 1WorldSync. Technische Änderungen und Irrtümer vorbehalten.