

Samsung Galaxy S25 Enterprise Edition 15,8 cm (6.2") Doppia SIM Android 15 5G USB tipo-C 12 GB 128 GB 4000 mAh Argento

Marchio : Samsung


Famiglia del prodotto: Galaxy **Codice prodotto:** SM-S931BZSDEEE

Nome del prodotto : Galaxy S25 Enterprise Edition

Samsung Galaxy S25 Enterprise Edition . Dimensioni diagonale schermo: 15,8 cm (6.2"), Risoluzione del display: 2340 x 1080 Pixel. Famiglia processore: Qualcomm Snapdragon, Modello del processore: 8 Elite. Capacità della RAM: 12 GB, Capacità memoria interna: 128 GB. Risoluzione fotocamera posteriore (numerico): 50 MP, Tipo di fotocamera posteriore: Tripla fotocamera. Capacità della scheda SIM: Doppia SIM. Sistema operativo incluso: Android 15. Capacità della batteria: 4000 mAh. Colore del prodotto: Argento. Peso: 162 g

Display		Camera	
Display diagonal *	15.8 cm (6.2")	Slow motion rate	240fps in FHD, 120fps in FHD, 120fps in UHD
Screen shape	Flat	Camera image formats supported	DNG, HEIF, JPEG
Display technology marketing name	Dynamic AMOLED 2X	Network	
Panel type	AMOLED	SIM card capability *	Dual SIM
Display glass type	Gorilla Glass	Mobile network generation *	5G
Gorilla Glass version	Gorilla Glass Victus 2	SIM card type *	NanoSIM + eSIM
Display resolution *	2340 x 1080 pixels	3G standards *	UMTS, WCDMA
Display number of colours	16 million colours	4G standard *	LTE-TDD & LTE-FDD
Maximum refresh rate	120 Hz	5G standard *	Sub6 FDD, Sub6 SDL, Sub6 TDD
Display brightness	1500 cd/m ²	Wi-Fi	✓
Pixel density	418 ppi	Top Wi-Fi standard *	Wi-Fi 7 (802.11be)
Brand specific technologies	Always-on display	Wi-Fi standards	802.11a, 802.11b, 802.11g, Wi-Fi 4 (802.11n), Wi-Fi 5 (802.11ac), Wi-Fi 6 (802.11ax), Wi-Fi 6E (802.11ax), Wi-Fi 7 (802.11be)
Rounded display corners	✓	Bluetooth *	✓
Processor		Bluetooth version	5.4
Processor family *	Qualcomm Snapdragon	3G bands supported	850,900,1900,2100 MHz
Processor model *	8 Elite	4G bands supported	700,800,850,900,1500,1800,1900,2100,2300,2600 MHz
Processor cores	8	5G bands supported	700,800,850,900,1500,1800,1900,2100,2300,2500,2600,3500,3700 MHz
Processor boost frequency	4.47 GHz	4G data rate (max)	2000 Mbit/s
Artificial Intelligence processor family	Qualcomm	5G data rate (max)	4.66 Gbit/s
Storage		Wi-Fi Direct	✓
RAM capacity *	12 GB	MIMO	✓
Internal storage capacity *	128 GB	Modulation	4096-QAM
Compatible memory cards *	Not supported	Near Field Communication (NFC)	✓
Camera		Ports & interfaces	
Rear camera sensor size	1/1.56"	USB port	✓
Second rear camera sensor size	1/3.94"	USB connector type	USB Type-C
Third rear camera sensor size	1/2.55"	Headphone connectivity	USB Type-C
Rear camera resolution (numeric) *	50 MP	Design	
Second rear camera resolution (numeric)	10 MP	Form factor *	Bar
Third rear camera resolution (numeric)	12 MP	Product colour *	Silver
Rear camera aperture number	1.8	Colour name	SilverShadow
Second rear camera aperture number	2.4	International Protection (IP) code	IP68
Third rear camera aperture number	2.2	Performance	
Rear camera pixel size	1 µm	Fast charging	✓
Rear camera pixel size (Quad Pixel technology)	1 µm	Wireless charging	✓
Second rear camera pixel size	1.4 µm	Fingerprint reader	✓
Navigation		Face recognition	✓
		GPS (satellite)	✓
		GLONASS	✓
		BeiDou	✓
		Galileo	✓

Camera		Navigation	
Rear camera field of view (FOV) angle	85°	Quasi-Zenith Satellite System (QZSS)	✓
Second rear camera field of view (FOV) angle	36°	Position location *	✓
Third rear camera field of view (FOV) angle	120°	Multimedia	
Optical zoom	3x	Audio formats supported	3GA, AAC, AMR, APE, AWB, DFF, DSF, FLAC, IMY, M4A, Mid, MIDI, MP3, MXMF, OGA, OGG, OTA, RTTTL, RTX, WAV, XMF
Digital zoom	30x	Video formats supported	3G2, 3GP, AVI, FLV, MKV, MP4, WEBM
Front camera type *	Single camera	Software	
Front camera sensor size	1/3.2"	Platform *	Android
Front camera resolution (numeric) *	12 MP	Operating system installed *	Android 15
Front camera aperture number	2.2	Battery	
Front camera pixel size	1.12 µm	Battery capacity *	4000 mAh
Front camera field of view (FOV) angle	80°	Sensors	
Rear camera flash *	✓	Proximity sensor	✓
Flash type	LED	Accelerometer	✓
Video capture resolution (max)	4320 x 7680 pixels	Ambient light sensor	✓
Maximum frame rate	240 fps	Gyroscope	✓
Resolution at capture speed	1280x720@30fps, 1920x1080@30fps, 1920x1080@60fps, 3840x2160@30fps, 3840x2160@60fps	Barometer	✓
Video recording modes	720p, 1080p, 2160p, 4320p	Geomagnetic sensor	✓
Rear camera type *	Triple camera	Hall sensor	✓
Auto focus	✓	Power	
Image stabilizer	✓	USB Type-C charging port	✓
Image stabilizer type	Optical Image Stabilization (OIS)	USB Power Delivery (USB PD)	✓
Night mode	✓	USB Type-C required charging power (min) *	10 W
Panorama	✓	USB Type-C required charging power (max) *	25 W
Portrait mode	✓	Weight & dimensions	
Slow motion mode	✓	Width	70.5 mm
		Depth	7.2 mm
		Height	146.9 mm
		Weight *	162 g
		Packaging content	
		AC adapter included *	✗

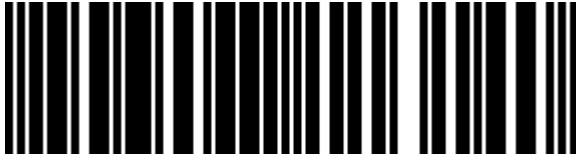

8806097113140

Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.

Publication date: 29-MAR-2025. Prints or copies of Information are only valid on the printed Publication date