

Samsung Galaxy A56 5G Enterprise Edition 17 cm (6.7") Doppia SIM USB tipo-C 8 GB 256 GB 5000 mAh Grafite

Marchio : Samsung

Famiglia del prodotto: Galaxy **Codice prodotto:** SM-A566BZKCEE


Nome del prodotto : Galaxy A56 5G Enterprise Edition

Samsung Galaxy A56 5G Enterprise Edition . Dimensioni diagonale schermo: 17 cm (6.7"), Risoluzione del display: 2340 x 1080 Pixel. Frequenza del processore: 1,9 GHz, Famiglia processore: Samsung Exynos, Modello del processore: 1580. Capacità della RAM: 8 GB, Capacità memoria interna: 256 GB. Risoluzione fotocamera posteriore (numerico): 50 MP, Tipo di fotocamera posteriore: Tripla fotocamera. Capacità della scheda SIM: Doppia SIM. Capacità della batteria: 5000 mAh. Colore del prodotto: Grafite. Peso: 198 g



Display		Network	
Display diagonal *	17 cm (6.7")	Modulation	1024-QAM
Screen shape	Flat	Near Field Communication (NFC)	✓
Display technology marketing name	Super AMOLED	Ports & interfaces	
Panel type	AMOLED	USB connector type	USB Type-C
Display glass type	Gorilla Glass	USB version	2.0
Gorilla Glass version	Gorilla Glass Victus+	Headphone connectivity	USB Type-C
Display resolution *	2340 x 1080 pixels	Messaging	
Display number of colours	16 million colours	Short Message Service (SMS)	✓
Maximum refresh rate	120 Hz	Multimedia Messaging Service (MMS)	✓
Processor		E-mail	✓
Processor family *	Samsung Exynos	Design	
Processor model *	1580	Form factor *	Bar
Processor cores	8	Product colour *	Graphite
Processor boost frequency	2.9 GHz	Colour name	Awesome Graphite
Processor frequency *	1.9 GHz	International Protection (IP) code	IP67
Storage		Performance	
User memory	234.4 GB	Video call	✓
RAM capacity *	8 GB	Fast charging	✓
Internal storage capacity *	256 GB	Fingerprint reader	✓
Compatible memory cards *	Not supported	Hearing aid compatibility	✓
Camera			
Rear camera resolution (numeric) *	50 MP		

Camera		Navigation	
Second rear camera resolution (numeric)	12 MP	GPS (satellite)	✓
Third rear camera resolution (numeric)	5 MP	GLONASS	✓
Rear camera aperture number	1.8	BeiDou	✓
Second rear camera aperture number	2.2	Galileo	✓
Third rear camera aperture number	2.4	Quasi-Zenith Satellite System (QZSS)	✓
Digital zoom	10x	Electronic compass	✓
Front camera type *	Single camera	Position location *	✓
Front camera resolution (numeric) *	12 MP	Multimedia	
Front camera aperture number	2.2	Speakers	stereo
Rear camera flash *	✓	Audio formats supported	3GA, AAC, AMR, AWB, FLAC, IMY, M4A, Mid, MIDI, MP3, MXMF, OGA, OGG, OTA, RTTTL, RTX, WAV, XMF
Video capture resolution (max)	3840 x 2160 pixels	Video formats supported	3G2, 3GP, AVI, FLV, M4V, MKV, MP4, WEBM
Maximum frame rate	240 fps	Software	
Resolution at capture speed	1280x720@240fps, 3840x2160@30fps	Platform *	Android
Rear camera type *	Triple camera	App distribution platform	Google Play
Auto focus	✓	Battery	
Image stabilizer	✓	Removable battery	✗
Image stabilizer type	Optical Image Stabilization (OIS)	Battery capacity *	5000 mAh
Macro photography	✓	Continuous video playback time	29 h
Slow motion mode	✓	Sensors	
Network		Proximity sensor	✓
SIM card capability *	Dual SIM	Accelerometer	✓
Mobile network generation *	5G	Ambient light sensor	✓
SIM card type *	NanoSIM + eSIM	Gyroscope	✓
3G standards *	UMTS, WCDMA	Power	
4G standard *	LTE-TDD & LTE-FDD	USB Type-C charging port	✓
5G standard *	Sub6 FDD, Sub6 TDD	USB Power Delivery (USB PD)	✓
Top Wi-Fi standard *	Wi-Fi 6 (802.11ax)	USB Type-C required charging power (min) *	10 W
Wi-Fi standards	802.11a, 802.11b, 802.11g, Wi-Fi 4 (802.11n), Wi-Fi 5 (802.11ac), Wi-Fi 6 (802.11ax)	USB Type-C required charging power (max) *	45 W
Bluetooth *	✓	Weight & dimensions	
Bluetooth version	5.3	Width	77.5 mm
3G bands supported	850,900,1900,2100 MHz	Depth	7.4 mm
4G bands supported	700,800,850,900,1500,1800,1900,2100,2300,2500,2600 MHz	Height	162.2 mm
5G bands supported	700,800,850,900,1800,2100,2300,2500,2600,3500,3700 MHz	Weight *	198 g
Wi-Fi Direct	✓	Packaging content	
MIMO	✓	AC adapter included *	✗
		Cables included	USB Type-C to USB Type-C
		SIM card ejector pin	✓

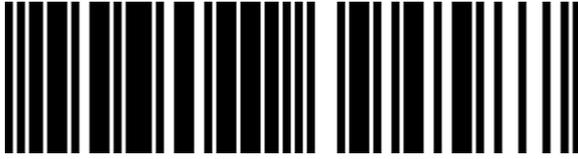

8806097394587

Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.

Publication date: 04-MAY-2025. Prints or copies of Information are only valid on the printed Publication date