

## VOLTCRAFT - RELIABLE AND PRECISE. SINCE 1982.

For more than 40 years, our product range has been dynamically adapting to the constant changes in the industry. We commit to offering first-class quality to our customers while delivering an excellent cost-performance ratio. This philosophy remains the cornerstone of Voltcraft's success.

## TEST LEADS LANTERN TYPE, RED + BLACK PAIR

Item no. 108495 MS-4P

### FEATURES

1.2m silicone test leads // CAT III 1000V CAT IV 600V, 10A // Double insulation cable


### PACKAGE CONTENTS

Test lead x 1 pair

### TECHNICAL DATA

| Item                  | Value                                |
|-----------------------|--------------------------------------|
| Rated voltage         | CAT III 1000V CAT IV 600V            |
| Rated current         | 10 A                                 |
| Cable length          | 1.2 m                                |
| Cable size            | Ø 3.6mm (18 AWG)                     |
| Insulation material   | PP + TPE                             |
| Contact material      | Nickel plated brass                  |
| Connection            | A: 4mm slatted plug<br>B: Test probe |
| Operating temperature | -5 to +45 °C                         |
| Operating humidity    | <85 % RH                             |
| Storage temperature   | -10 to +50 °C                        |
| Storage humidity      | <85 % RH                             |
| Dimensions (L x Ø)    | 1394 x 33 mm                         |
| Color                 | Red + Black                          |
| Weight                | 90 g                                 |

### DIMENSIONS

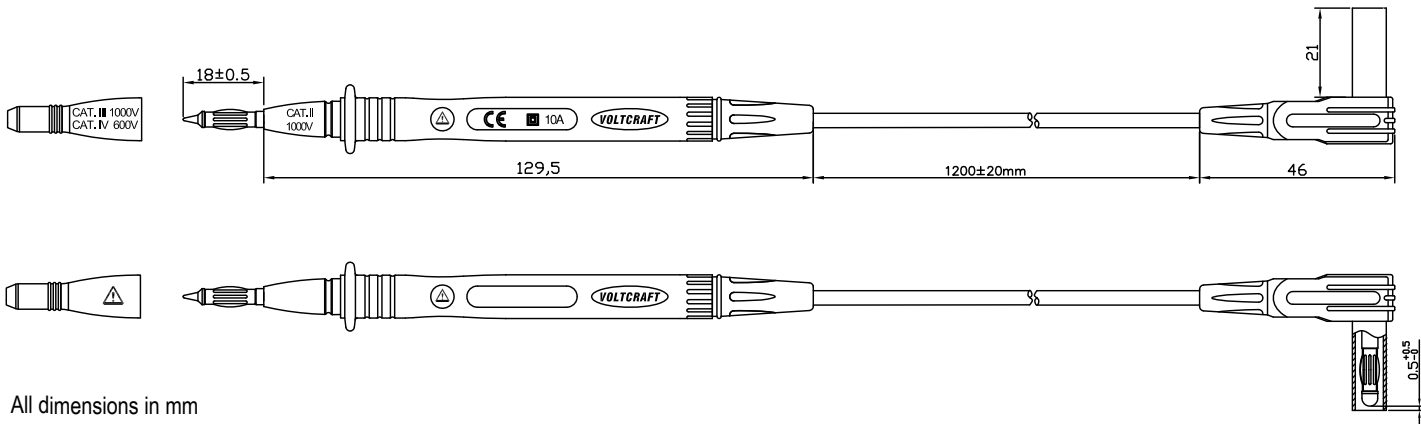

All dimensions in mm