
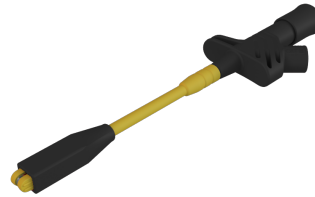


Clamp-type test probe

KLEPS 2800

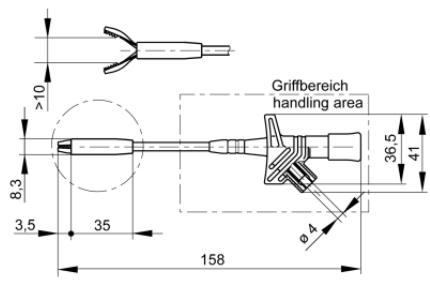

Product	KLEPS 2800
description	Safety clamp-type test probe with insulated wide opening grip claws for contacting large measuring areas and leads with large cross-sections. 4 mm brass socket connection. Connects with safety measuring leads.
operating instruction	BA458
article-no. / *colour	9723081xx  00 black  01 red
drawing	
	
technical data	
connection	unsprung socket 4 mm
rated voltage	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT III
rated current (consider derating curve)	20 A
material plug	spring steel
material socket	brass
housing material	PBT
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB
clamp type	grip claws, nickel plated

4 mm safety system

clamping range	10 mm
----------------	-------

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges
stand: 21.06.2022

stand: 21.06.2022