


Crocodile clips

AGF 30

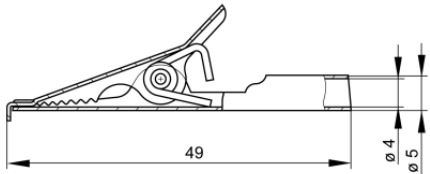

Product	AGF 30
description	Stainless steel alligator clip. The special shape allows clamping of both extremely fine and thick wires. Maximum bolt diameter 10 mm. connection type: 4 mm diameter socket Rust-proof, acid-proof and non-magnetic.
operating instruction	BA420
Articlenummer	930122000
drawing	
	
technical data	
connection	unsprung socket 4 mm
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	4 A
material socket	stainless steel
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +100 °C
clamping range	10 mm

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains

stand: 21.06.2022

stand: 21.06.2022

4 mm system