

VOLTCRAFT - RELIABLE AND PRECISE. SINCE 1982.

For more than 40 years, our product range has been dynamically adapting to the constant changes in the industry. We commit to offering first-class quality to our customers while delivering an excellent cost-performance ratio. This philosophy remains the cornerstone of Voltcraft's success.

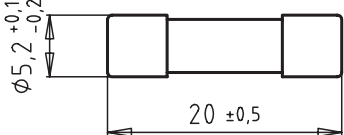
FUSE 5 X 20 MM

Item no. 123421

FEATURES

660 V // 500 mA / Super-fast acting FF // short circuit protection only

TECHNICAL DATA

Application			
Short circuit protection only			
Construction			
Ceramic tube	Non-transparent with filling		
End caps	Brass, nickel-plated		
			
All dimensions in mm			
Rating			
Type	aR (FF)		
Rated Current	500 mA		
Rated Breaking Capacity	100 kA @ AC/DC 660 V		
Voltage Drop	550 mV		
Power Dissipation (@1,0 I _n)	0.3 W		
I ² t _s Value	0.07 A²s		
Fusing time limits	Rated current	min.	max.
1 I _n	100 mA - 500 mA	1 h	-
2 I _n	100 mA - 500 mA	-	-
2,75 I _n	100 mA - 500 mA	-	-
4 I _n	100 mA - 500 mA	-	60 ms
10 I _n	100 mA - 500 mA	-	6 ms

PACKAGE CONTENTS

1x Fuse

