


SAUTER AC 01

Screw Tension Clamp for tension and rupture tests

KERN

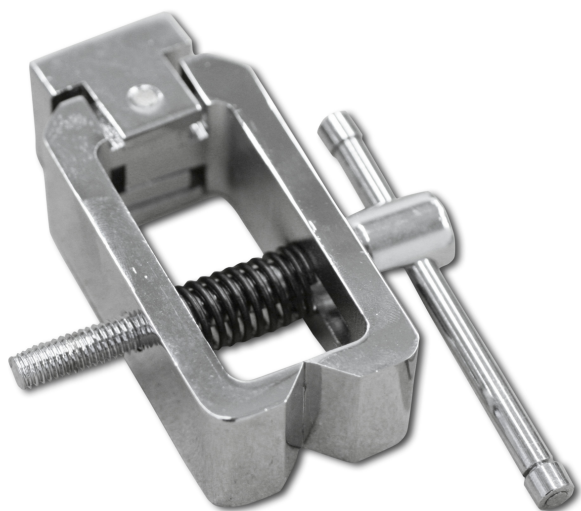

Pictograms

STANDARD



Category

Brand	Sauter
Product category	Clamp
Product group	Screw tension clamp

Construction

Dimensions completely mounted (W×D×H)	75×65×20 mm
Material	steel
Mounting - force dissipation	Threaded hole M6
Maximum clamp width	20 mm
Clamping width	20 mm
Tensile/compressive force [Max]	500 N

Environmental conditions

Storage temperature [Min]	-10 °C
Storage temperature [Max]	40 °C

Packing & Shipping

Delivery time	1 d
Dimensions packaging (W×D×H)	75×65×20 mm
Shipping method	Parcel service
Net weight approx.	0,45 kg
Gross weight approx.	0,45 kg
Shipping weight	0,435 kg

Product information

GTIN/EAN number	4045761121737
REACH classification	no prohibited substances