


SAUTER AC 14

Standard Screw Tension Clamp for tension and rupture tests

KERN

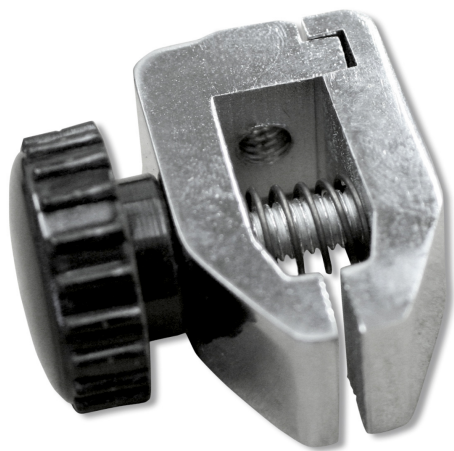

Pictograms

STANDARD



Category

Brand	Sauter
Product category	Clamp
Product group	Screw tension clamp

Construction

Dimensions completely mounted (W×D×H)	40×36×16 mm
Material	steel
Material housing	metal
Mounting - force dissipation	Threaded hole M6
Maximum clamp width	16 mm
Clamping width	4 mm
Tensile/compressive force [Max]	500 N

Environmental conditions

Storage temperature [Min]	-10 °C
Storage temperature [Max]	40 °C

Packing & Shipping

Delivery time	1 d
Dimensions packaging (W×D×H)	150×100×10 mm
Shipping method	Parcel service
Net weight approx.	0,20 kg
Gross weight approx.	0,25 kg
Shipping weight	0,21 kg

Product information

GTIN/EAN number	4045761122376
REACH classification	no prohibited substances