


► (RTS) Bayonet Bore Type
RTS-M06-L050-K02




Max. operating temperature : -50 °C / +200 °C
Standard cable types : Silicone + Silicone
Sensor type : DIN/EN60751 Class "B" 1xPT-100
Protection tube material : AISI304 (DIN1.4301) Stainless Steel

► Technical drawing

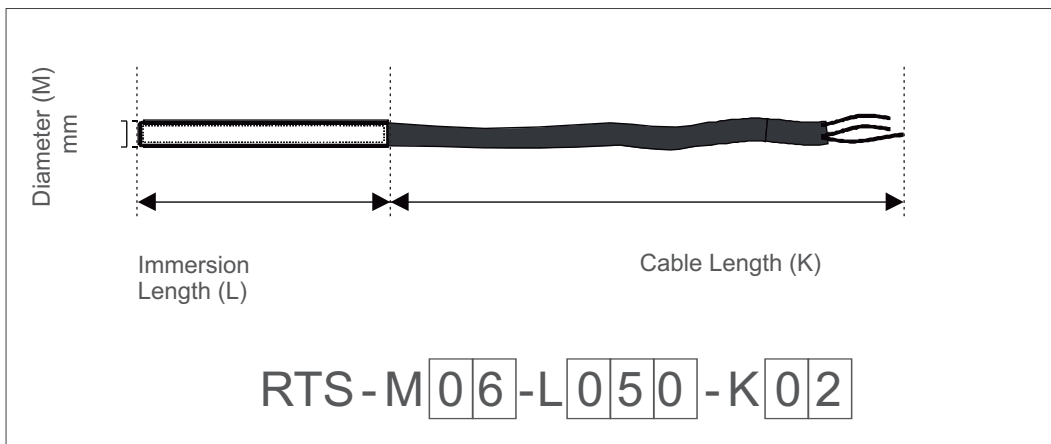

PT-100 Connections

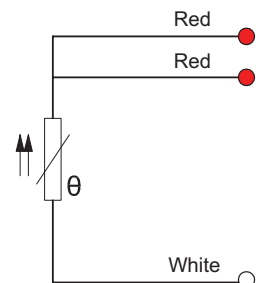

Diameter (M) : 6 mm
Immersion Length (L) : 50 mm
Cable length (K) : 2 meter