


► (TCS) Bayonet Bore Type  
TCS-M06-L060-K02.J



Max. operating temperature : -50 °C / +200 °C  
 Standard cable types : Silicone + Silicone  
 Sensor type : DIN/IEC-584 "J" FeCu-Ni E=J  
 Protection tube material : AISI304 (DIN1.4301) Stainless Steel

► Technical drawing

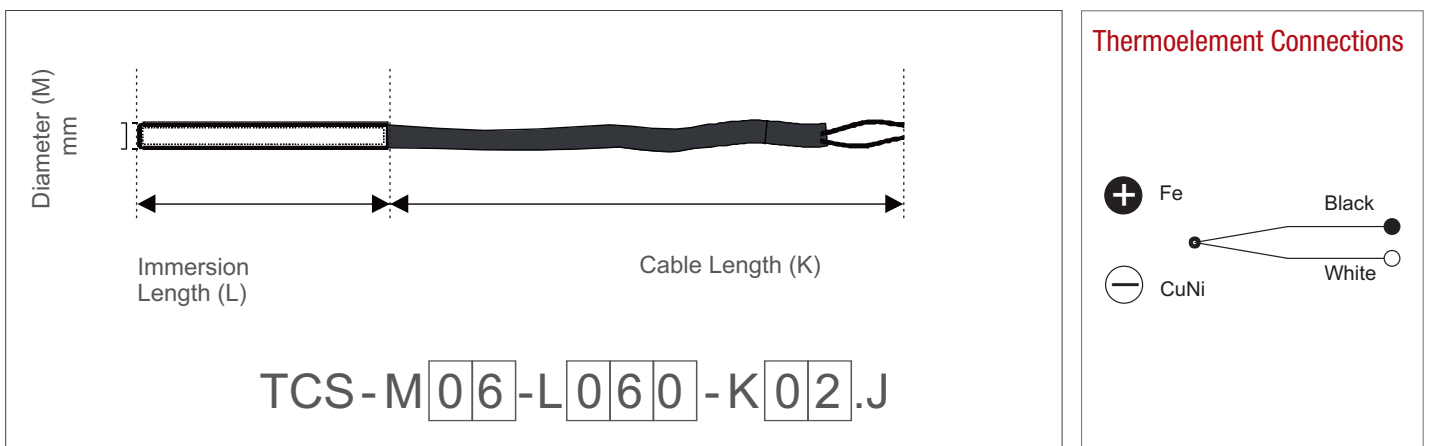

Diameter (M) : 6 mm  
 Immersion Length (L) : 60 mm  
 Cable length (K) : 2 meter