


Measuring leads

MAL N 4-0,64/100-0,25

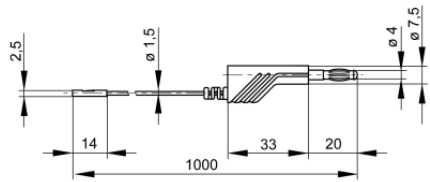

Product	MAL N 4-0,64/100-0,25
description	Injection-moulded measuring lead with sprung 4 mm diameter plug and 4 mm diameter socket for further connection and insulated socket for 0.64 mm round pillar and 0.64 mm rectangular pillar. Highly flexible 0.25 mm ² stranded wire.
operating instruction	BA001
article-no. / *colour	9341601xx  00 black  01 red
drawing	
technical data	
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	3 A
material socket	contact pin: brass contact spring / contact socket: copper - beryllium
housing material	PVC / PPO
temperature range acc. To IEC61010 ⁽¹⁾	-15 °C to +70 °C
cable length	100 cm
conductor size	0,25 mm ²
cable material	PVC

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains

stand: 21.06.2022

stand: 21.06.2022