


Clamp-type test probe

KLEPS 30

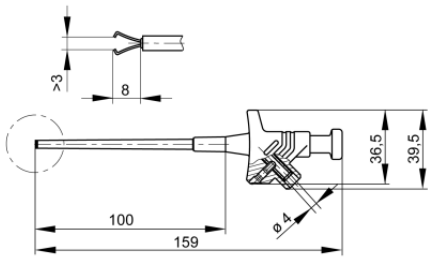

Product	KLEPS 30
description	Clamp-type test probe with rotating grip jaws and flexible shaft. The special form of the grip jaws allows clamping of pins and wires up to a maximum of 4mm diameter. 4mm diameter brass socket connection with side screw, grip jaws additionally tin-plated.
operating instruction	BA408
article-no. / *colour	9301131xx ● 00 black ● 01 red
drawing	
technical data	
connection	4 mm socket (unsprung) screw terminal
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	4 A
material socket	brass
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	V-0
clamp type	rotating grip jaws, tin plated

4 mm system

clamping range	4 mm
----------------	------

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains

stand: 21.06.2022

stand: 21.06.2022