


Clamp-type test probe

KLEPS 2700

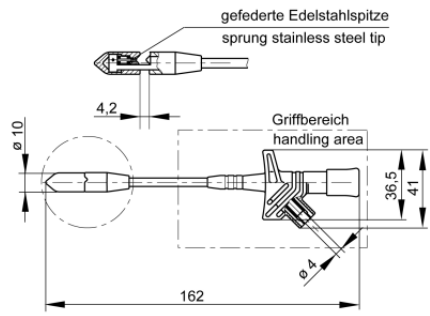

Product	KLEPS 2700
description	Clamp-type test probe with split test clamp. The sprung stainless steel tip can contact insulated leads with cross-sections between 0.25 mm ² and 1.5 mm ² (3.5 mm diameter) without the need to strip them. 4 mm diameter brass socket connection.
operating instruction	BA408
article-no. / *colour	● 00 black ● 01 red
drawing	
	
technical data	
connection	unsprung socket 4 mm
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	10 A
material plug	stainless steel, nickel plated
material socket	brass
housing material	PBT
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB

4 mm system

clamp type	stainless steel tip
clamping range	3,5 mm

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains
 stand: 21.06.2022

stand: 21.06.2022