

VOLTCRAFT - RELIABLE AND PRECISE. SINCE 1982.

For decades, our product range has been dynamically adapting to the constant changes in the industry.

We commit to offering first-class quality to our customers while delivering an excellent cost-performance ratio. This philosophy remains the cornerstone of Voltcraft's success.


IC TEST CLIP



Item no. 138428 (RED)

Item no. 138436 (BLACK)

DIMENSIONS

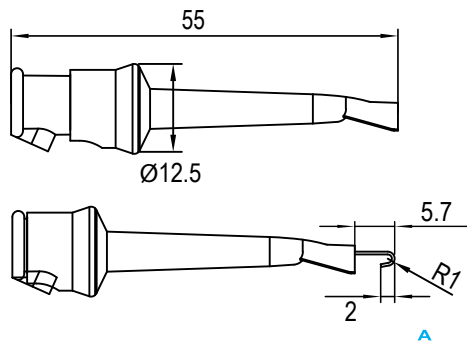

All dimensions in mm

FEATURES

CAT I // 1A // Clamping range diameter 4 mm //
Solder connection for wires < 2 mm

TECHNICAL DATA

Voltage category	CAT I 30 VAC / 60 VDC
Rated current	max. 3 A
Clamping range diameter	4 mm
Colour	Item 138428 Red, Item 138436 Black
Plastic material	ABS
Contact material	Phosphor Bronze
Operating condition	-5 to +45 °C, <85% RH
Storage condition	-10 to +50 °C, <85% RH
Compatible cable	max. 3.5 mm
Dimension (Ø x L)	12.5 x 55 mm
Weight	14 g / pc



PACKAGE CONTENTS

Test Clip