

# Indicator Lights - Sealed to IP67

## Colours and voltages:

-  **Neon** Available with Red, Amber, Green or Clear lenses  
200/250V (marked 230V)
-  **LED - DC** Red, Yellow, Green  
LED with resistor for 12V dc, 24V dc
-  **LED - AC** Red, Yellow, Green, Blue  
110-230V ac operation.







 







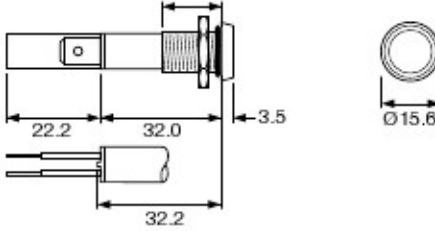




 


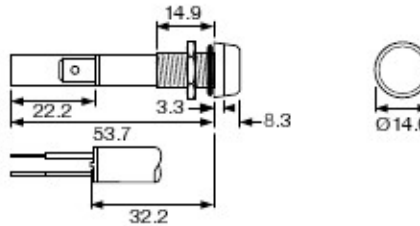
- ▶ IP67 Panel Sealing
- ▶ Supplied complete with gaskets/'O' rings
- ▶ Neon, LED, mains LED or filament lamp
- ▶ Bezel sizes from 7.6 to 22.9mm diameter
- ▶ Red, amber, green, blue and clear lenses
- ▶ Red, yellow, green, blue and white LEDs
- ▶ Wide choice of styles

KEBA  
KEUR

**RoHS** RoHS compliant

## To create a catalogue number:

Refer to the 2 columns below (terminal and type), then state: Lens colour, voltage and whether neon, LED or filament lamp

| TERM  | TYPE   | PANEL  | ILLUMINATION OPTIONS  | DIMENSIONS (mm)  |
|---|--|--|---|--|
| L        | (L) <b>1041 OS</b> Chrome bezel<br><br>KEBA   |  6.3<br> 5.3 max       | <br>  | <br>9.9, 4.5, Ø9.5                            |
| C 6.3  | (C) <b>0275 OS</b> Chrome bezel<br><br>KEBA |  10.0<br> 11.5 max | <br><br> | <br>22.2, 32.0, 3.5, 32.2, Ø15.6             |
| C 6.3  | (C) <b>0277 OS</b> Chrome bezel<br><br>KEBA |  10.0<br> 11.5 max | <br><br> | <br>14.9, 22.2, 3.3, 53.7, 8.3, 32.2, Ø14.6 |