

# Indicator Lights - Sealed to IP67

## Colours and voltages:

-  **Neon** Available with Red, Amber, Green or Clear lenses  
200/250V (marked 230V)
-  **LED - DC** Red, Yellow, Green  
LED with resistor for 12V dc, 24V dc
-  **LED - AC** Red, Yellow, Green, Blue  
110-230V ac operation.

- ▶ IP67 Panel Sealing
- ▶ Supplied complete with gaskets/'O' rings
- ▶ Neon, LED, mains LED or filament lamp
- ▶ Bezel sizes from 7.6 to 22.9mm diameter
- ▶ Red, amber, green, blue and clear lenses
- ▶ Red, yellow, green, blue and white LEDs
- ▶ Wide choice of styles



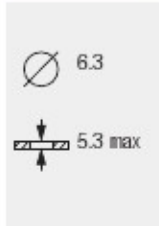

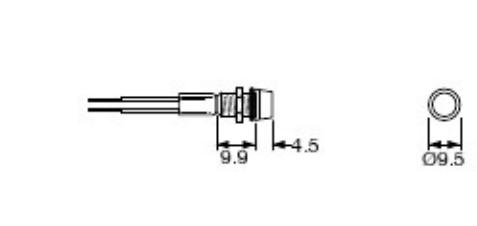



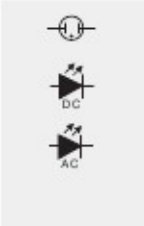
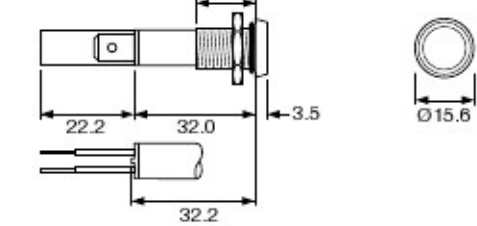


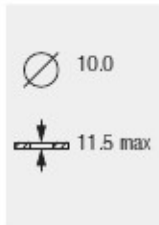

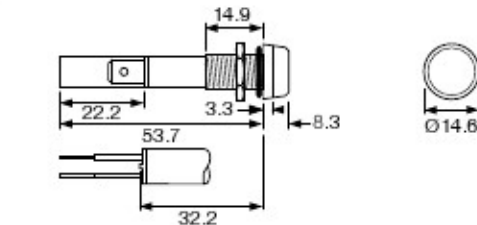







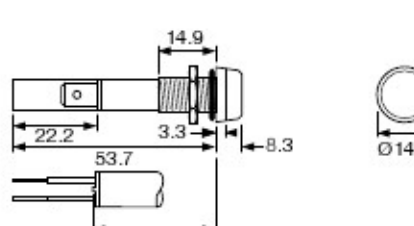
**KEMA**  
KEUR

**RoHS**

RoHS compliant

## To create a catalogue number:

Refer to the 2 columns below (terminal and type), then state: Lens colour, voltage and whether neon, LED or filament lamp

TERM	TYPE	PANEL	ILLUMINATION OPTIONS	DIMENSIONS (mm)
L 	(L) 1041 OS Chrome bezel 	 6.3  5.3 max	 	 9.9, 4.5, Ø9.5
C 6.3 	(C) 0275 OS Chrome bezel 	 10.0  11.5 max	  	 22.2, 32.0, 3.5, 32.2, Ø15.6
C 6.3 	(C) 0277 OS Chrome bezel 	 10.0  11.5 max	  	 14.9, 22.2, 3.3, 53.7, 8.3, 32.2, Ø14.6