


RS232-ADC16/24

Analog digital converter in housing

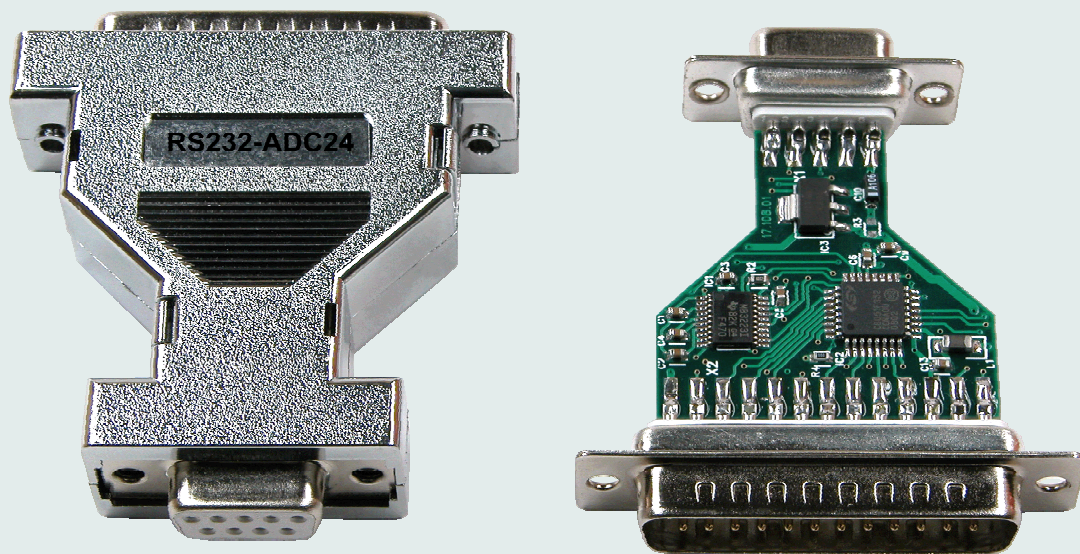

Technical summary

- RS232 interface
- Eight analog 16/24-bit inputs
- Eight digital 3.3V IOs (5V tolerant)
- Extended temperature range (-40°C – 85°C)
- Access via C-library
- Dimensions: 62 x 55 (33) x 17 mm