


Product information

8 ports, 5-10 M - SB 8/LED 3-333/5 M

Industrial Connecting Solutions:I/O Modules:Passive distributors:M8 Passive Distributors:fixed control cable:8 ports, sensor distribution box:8 ports, 5-10 M

https://e-catalog.hirschmann.com:443/link/57078-24228-255441-199791-199792-204935-249791-205053/en/SB_08_LED3_333_05/ui/state

Name	8 ports, 5-10 M
	
	Miniature sensor distribution box, 8-port version, with integrated LED operation and function indicators, M8-sockets, 3-pole, fixed control cable, PUR jacket, halogen free, black, 5 meter.
Delivery informations	
Availability	available
Product description	
Type	SB 8/LED 3-333/5 M
Order No.	60637
Description	Miniature sensor distribution box, 8-port version, with integrated LED operation and function indicators, M8-sockets, 3-pole, fixed control cable, PUR jacket, halogen free, black, 5 meter.
Number of contacts	3 (M8)
Version	8 ports
Color of housing	orange
Product characteristics	Vibration resistance, Oil resistance, Drag chains suitable
Classification	
Belden brand	Lumberg-Automation
Mechanical data	
Thread	M8
LED display present	✓
Environmental conditions	
Environmental temperature	-15 °C ... 80 °C
Degree of protection (IP), mounted	IP67
Pollution degree	3
Materials	
Housing material / Molded body	TPU, self-extinguishing
Contact bearer material	TPU, self-extinguishing
Contact material	CuZn
Contact material - Surface refinement	pre-nickel and 0.8 microns gold-plated
Knurled screw / nut material	CuZn, nickel-plated
Sealing material	FKM
Electrical data	
Contact resistance	≤ 5 mΩ
Rated current In	2 A per socket / 2 A max. at 40 °C
Nominal voltage	10 - 30 V DC
Insulation resistance	> 1 GΩ
Approvals	
Approvals	cURus
Cable	
Cable length	5 m
Cable number	333
Cable description	Control cable
Color of jacket	black
Material of outer jacket	PUR
Outer diameter of the cable	8.8 mm
Number of conductors	10

Industrial Connecting Solutions:I/O Modules:Passive distributors:M8 Passive Distributors:fixed control cable:8 ports, sensor distribution box:8 ports, 5-10 M

https://e-catalog.hirschmann.com:443/link/57078-24228-255441-199791-199792-204935-249791-205053/en/SB_08_LED3_333_05/ui/state

Cable design 2 x 0.5 mm² + 8 x 0.34 mm²


Flame resistant according to standard IEC 60332-2, CSA FT-2

Scope of delivery and accessories

Scope of delivery ZVK: 2 dust covers for unused sockets
1 attachable label

Picture

Drawing

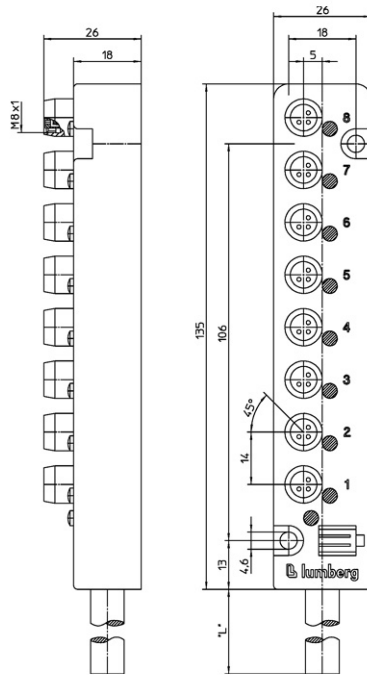

Belden Deutschland GmbH

Im Gewerbepark 2
58579 Schalksmühle
Germany
Phone: +49 7127/14-1806
E-Mail: icos-sales@belden.com

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.